


Geçmeli Nipel


İç diş

A (Bağlantı)	SW mm	U mm	Art.-Nr.	Amb./Ad.
R 1/4"	17	33	0699 201 4	5
R 3/8"	19		0699 203 8	
R 1/2"	24		0699 201 2	

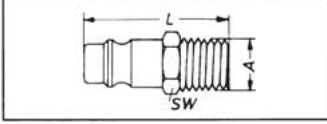

Dış diş


A (Bağlantı)	SW mm	U mm	Art.-Nr.	Amb./Ad.
R 1/4"	17	32	0699 211 4	5
R 3/8"	19		0699 213 8	
R 1/2"	24	36	0699 211 2	

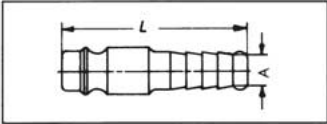

Geçmeli Ağzılık


Hortum bağlantısı

A (Bağlantı)	U mm	Art.-Nr.	Amb./Ad.
6 mm	48	0699 36	5
9 mm		0699 39	
13 mm		0699 313	

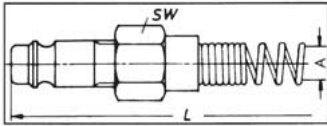

Spiral Hortum Bağlantısı


A (Bağlantı)	SW mm	U mm	Art.-Nr.	Amb./Ad.
6 x 8 mm	17	33	0699 368	3
9 x 12 mm	19	47	0699 391 2	

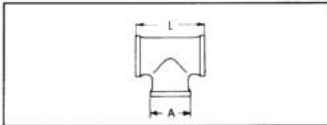

T Parçası


İç diş

A (Bağlantı)	U mm	Art.-Nr.	Amb./Ad.
R 1/4"	35	0699 641 4	3
R 3/8"	43	0699 643 8	
R 1/2"	50	0699 641 2	

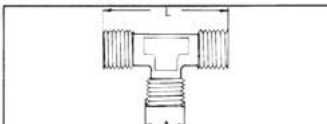


Dış diş

A (Bağlantı)	U mm	Art.-Nr.	Amb./Ad.
R 1/4"	41	0699 651 4	3
R 3/8"	48	0699 653 8	

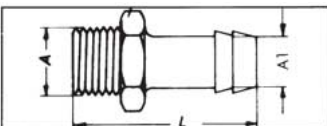


Dişli Ağzılık

Bağlantı A	Bağlantı A1	SW mm	U mm	Art.-Nr.	Amb./Ad.
R 1/8"	6	13	39	0699 461 8	5
R 1/4"		17		0699 461 4	
R 3/8"		19		0699 463 8	
R 1/8"	9	13	36	0699 491 8	
R 1/4"		17		0699 491 4	
R 3/8"		19		0699 493 8	
R 1/2"	13	27	44	0699 491 2	
R 3/8"		19		0699 413 38	
R 1/2"		27		0699 413 12	

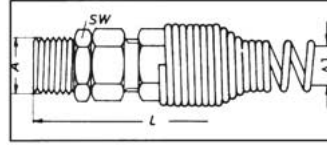


Spiral Hortum Bağlantısı döndürülebilir yaylı

Bağlantı A	Bağlantı A1	SW mm	U mm	Art.-Nr.	Amb./Ad.
R 1/4"	6 x 8	14	96	0699 414 68	1
R 3/8"	9 x 12	19		0699 438 912	

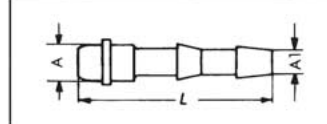

Hortum Ağzılığı


Bağlantı A	Bağlantı A1 mm	U mm	Art.-Nr.	Amb./Ad.
R 1/4"	6	47	0699 561 4	5
R 3/8"		47,5	0699 563 8	
R 1/2"		38	0699 561 2	
R 1/4"	9	35,5	0699 591 4	
R 3/8"		36	0699 593 8	
R 1/2"	13	46	0699 591 2	
		44	0699 513 12	

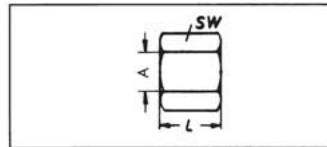

Başlıklı Somun 6 köşe


Sağ diş

A (Bağlantı)	SW mm	U mm	Art.-Nr.	Amb./Ad.
R 1/4" f. 6 mm	17	15	0699 516 14	5
R 1/4" f. 9 mm			0699 519 14	
R 3/8"	19	16	0699 516 38	
R 1/2"	24	20	0699 516 12	

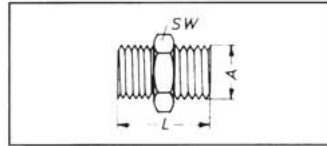


Konili Çift Nipel

A (Bağlantı)	SW mm	U mm	Art.-Nr.	Amb./Ad.
R 1/4"	17	23	0699 614 14	5
R 1/8" x R 1/4"			0699 614 141	
R 3/8"	19	23	0699 638 38	
R 1/4" x R 3/8"			0699 638 381	
R 1/2"	24	30	0699 612 12	

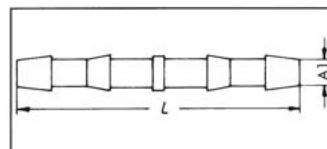

Çiftli Hortum Ağzılığı

A (Bağlantı)	U mm	Art.-Nr.	Amb./Ad.
6 mm	72	0699 76	5
9 mm		0699 79	
13 mm	74	0699 713	

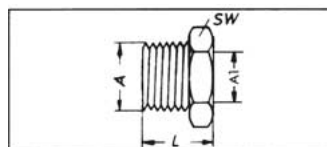

Redüksiyon Nipeli

Bağlantı A	Bağlantı A1	SW mm	U mm	Art.-Nr.	Amb./Ad.
R 1/4"	R 1/8"	17	11	0699 818 14	5
R 3/8"	R 1/4"	19	14	0699 814 38	
R 1/2"	R 3/8"	24	18	0699 838 12	