


ORSY

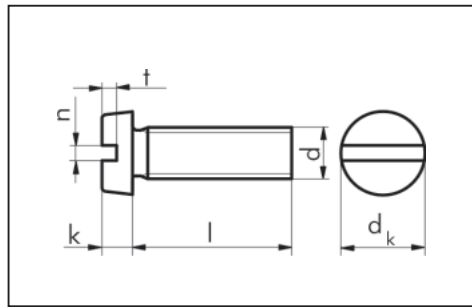

Zylinder- schrauben mit Schlitz nach DIN 84 (ISO 1207)

Messing blank (CuZn 37)
Stahl 4.8 blank
Stahl 4.8 verzinkt, blau passiviert
Stahl 4.8 verzinkt, gelb passiviert
A2
A4

Nenn-Ø d	M 2	M 2,5	M 3	M 3,5	M 4	M 5	M 6	M 8	M 10	M 12
dk mm	3,8	4,5	5,5	6,0	7,0	8,5	10,0	13,0	16,0	18,0
k mm	1,3	1,6	2,0	2,4	2,6	3,3	3,9	5,0	6,0	7,0
n mm	0,5	0,6	0,8	1,0	1,2	1,2	1,6	2,0	2,5	2,5
t mm	0,6	0,7	0,85	1,0	1,1	1,3	1,6	2,0	2,4	2,4



Sortimente

Zylinderschrauben mit Schlitz, DIN 84,
Stahl verzinkt, blau passiviert, 1350 Teile
Artikel:
0040 3 x 10/16/20/25
0040 4 x 10/16/20/25
0040 5 x 10/20/30/40
0040 6 x 16/20/25/30
Tiefziehteil, Art.-Nr. 0955 801 6

Art.-Nr. 0964 040

Zylinderschrauben mit Schlitz, DIN 84,
Edelstahl A2, 1340 Teile

Artikel:
0287 4 x 8/10/16/20
0287 5 x 8/10/12/16/20/30
0287 6 x 16/20/25/30/35/40
Tiefziehteil, Art.-Nr. 0955 801 6



Art.-Nr. 0964 287

Gewindeschrauben, DIN 963, DIN 84,
verzinkt, blau passiviert; Muttern DIN 934-8,
verzinkt, blau passiviert; Scheiben,
DIN 125A, verzinkt, blau passiviert 1200 Teile

Artikel:
0039 4 x 10/5 x 16/6 x 20
0040 4 x 10/16/20
0040 5 x 10/16/20
0040 6 x 16/20/25
0317 4/5/6
0407 4/5/6

Tiefziehteil, Art.-Nr. 0955 801 8

Art.-Nr. 0964 040 1

Nenn-Ø d	Länge l mm	Messing blank Art.-Nr.	VE/St.	Stahl 4.8 blank Art.-Nr.	VE/St.	Stahl 4.8 vz., blau pass. Art.-Nr.	VE/St.	Stahl 4.8 vz., gelb pass. Art.-Nr.	VE/St.	A2 Art.-Nr.	VE/St.	A4 Art.-Nr.	VE/St.
M 2	3			0040 02 3		0040 2 3	2000	0040 72 3					
	4	0001 2 4	500/2000	0040 02 4		0040 2 4		0040 72 4	2000	0287 2 4	1000		
	5	0001 2 5		0040 02 5		0040 2 5		0040 72 5		0287 2 5	50		
	6	0001 2 6		0040 02 6		0040 2 6	100/500	0040 72 6	500/2000	0287 2 6	1000		
	8	0001 2 8		0040 02 8		0040 2 8		0040 72 8		0287 2 8			
	10	0001 2 10		0040 02 10		0040 2 10	500	0040 72 10		0287 2 10	500		
	12	0001 2 12	200	0040 02 12	2000	0040 2 12	100/500	0040 72 12	2000				
	14	0001 2 14		0040 02 14		0040 2 14	2000						
	16	0001 2 16		0040 02 16		0040 2 16	100/500	0040 72 16					
	18			0040 02 18		0040 2 18	2000			0287 2 18	1000		
	20	0001 2 20	2000	0040 02 20		0040 2 20	100/500	0040 72 20					
M 2,5	3			0040 025 3		0040 25 3	2000			0287 25 3			
	4	0001 25 4		0040 025 4		0040 25 4		0040 725 4	2000	0287 25 4	1000		
	5	0001 25 5	2000	0040 025 5		0040 25 5	100	0040 725 5		0287 25 5			
	6	0001 25 6		0040 025 6		0040 25 6		0040 725 6		0287 25 6			
	8	0001 25 8	500	0040 025 8		0040 25 8		0040 725 8	500/2000	0287 25 8		0289 25 8	1000
	10	0001 25 10	2000	0040 025 10		0040 25 10		0040 725 10		0287 25 10	500		
	12	0001 25 12	200	0040 025 12	2000	0040 25 12	100/500	0040 725 12	500	0287 25 12	100		
	14	0001 25 14		0040 025 14		0040 25 14	2000	0040 725 14	2000	0287 25 14			
	16	0001 25 16	2000	0040 025 16		0040 25 16	100/500	0040 725 16	500	0287 25 16	1000		
	18			0040 025 18		0040 25 18	2000	0040 725 18	2000	0287 25 18	500	0289 25 18	2000
	20	0001 25 20	1000	0040 025 20		0040 25 20	100/500	0040 725 20	500	0287 25 20	200		
22			0040 025 22		0040 25 22	2000	0040 725 22	2000	0287 25 22	500			