


HUTMUTTERN

DIN 1587, hohe Form

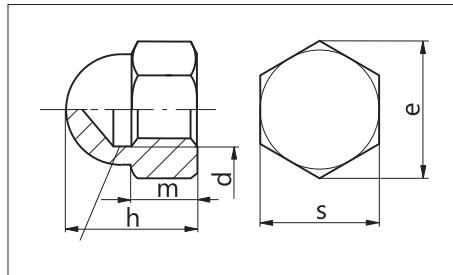

Stahl verzinkt, blau passiviert (A2K)

Stahl, gelb verzinkt (A2C)

Messing blank

Messing vernickelt

Messing verchromt

A2, A4

Gewinde d	e mm	h mm	m mm	s mm	Stahl vz., blau pass. (A2K) Art.-Nr.	VE St.	Stahl, gelb vz. (A2C) Art.-Nr.	VE St.	Messing blank Art.-Nr.	VE St.	Messing vernickelt Art.-Nr.	VE St.	Messing verchromt Art.-Nr.	VE St.
M 3	6,01	7,0	2,4	5,5	0356 3	100			0350 3	100	0352 43	100	0352 3	100
M 4	7,66	8,0	3,2	7	0356 4			0350 4	0352 44		0352 4			
M 5	8,79	10,0	4,0	8	0356 5			0350 5	0352 45		0352 5			
M 6	11,05	12,0	5,0	10	0356 6		0356 61	100	0350 6		0352 46		0352 6	
M 8	14,38	15,0	6,5	13	0356 8	50			0350 8	25	0352 48	50	0352 8	50
M 10	17,70	18,0	8,0	16	0356 10			0350 10	0352 410		0352 10			
M 10 x 1,25	17,70	18,0	8,0	14	0356 10 125									
M 12	20,03	22,0	10,0	18	0356 12			0350 12	25				0352 12	
M 12 x 1,5	20,03	22,0	10,0	18	0356 12 15	100								
M 14	23,35	25,0	11,0	21	0356 14	50			0350 14	100			0352 14	50
M 16	26,75	28,0	13,0	24	0356 16	25			0350 16	25			0352 16	25
M 20	33,53	34,0	16,0	30	0356 20	5/25			0350 20	5				
M 24	39,98	42,0	19,0	36	0356 24									

ORSY®-lagerfähig

Gewinde d	e mm	h mm	m mm	s mm	A2 Art.-Nr.	VE St.	A4 Art.-Nr.	VE St.
M 4	7,66	8,0	3,2	7	0348 4	100	0349 4	100
M 5	8,79	10,0	4,0	8	0348 5		0349 5	
M 6	11,05	12,0	5,0	10	0348 6		0349 6	
M 8	14,38	15,0	6,5	13	0348 8	50	0349 8	50
M 10	17,70	18,0	8,0	16	0348 10		0349 10	
M 12	20,03	22,0	10,0	18	0348 12		0349 12	
M 14	23,35	25,0	11,0	21	0348 14	100	0349 14	100
M 16	26,75	28,0	13,0	24	0348 16	50	0349 16	50
M 24	39,98	42,0	19,0	36			0349 24	

ORSY®-lagerfähig