




ORSY

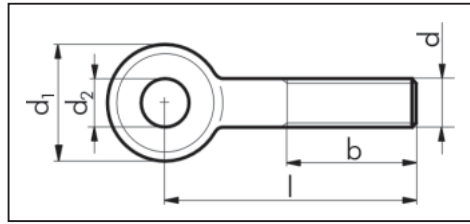

# Augenschrauben DIN 444 Form B

Stahl 4.6 verzinkt, blau passiviert

A2 A4

Gew.-Ø d	M5	M6	M8	M10	M12	M16
b (bis 125) mm	16	18	22	26	30	38
b (ab 125) mm	-	-	28	32	36	44
d <sub>1</sub> mm	12	14	18	20	25	32
d <sub>2</sub> mm	5	6	8	10	12	16

Gewinde-Ø d	l mm	Stahl vz., blau pass. Art.-Nr.	VE St.	A2  Art.-Nr.	VE St.	A4  Art.-Nr.	VE St.	
M 5	30	<b>0236 05 30</b>	200					
	35	<b>0236 05 35</b>						
	40	<b>0236 05 40</b>						
M 6	30	<b>0236 06 30</b>	200	<b>0101 6 30</b>	100	<b>0058 6 35</b>	100	
	35	<b>0236 06 35</b>		<b>0101 6 35</b>		<b>0058 6 40</b>		
	40	<b>0236 06 40</b>		<b>0101 6 40</b>				
	M 6	45	<b>0236 06 45</b>	100		100	<b>0058 6 50</b>	100
		50	<b>0236 06 50</b>					
		55	<b>0236 06 55</b>					
		60	<b>0236 06 60</b>		<b>0101 6 60</b>		<b>0058 6 60</b>	
80		<b>0236 06 80</b>						
M 8	25	<b>0236 08 25</b>	100		100	<b>0058 8 30</b>	100	
	30	<b>0236 08 30</b>						
	35	<b>0236 08 35</b>						
	40	<b>0236 08 40</b>		<b>0101 8 40</b>		<b>0058 8 40</b>		
	M 8	45	<b>0236 08 45</b>	50		100	<b>0058 8 50</b>	100
		50	<b>0236 08 50</b>		<b>0101 8 50</b>			
		55	<b>0236 08 55</b>		<b>0101 8 55</b>			
		60	<b>0236 08 60</b>		<b>0101 8 60</b>		<b>0058 8 60</b>	
		70	<b>0236 08 70</b>		<b>0101 8 70</b>		<b>0058 8 70</b>	
		80	<b>0236 08 80</b>		<b>0101 8 80</b>		<b>0058 8 80</b>	
90			<b>0101 8 90</b>		<b>0058 8 90</b>			
100		<b>0101 8 100</b>	<b>0058 8 100</b>					
M 10	40	<b>0236 010 40</b>	50		50	<b>0058 10 50</b>	50	
	45	<b>0236 010 45</b>						
	50	<b>0236 010 50</b>		<b>0101 10 50</b>		<b>0058 10 50</b>		
	55	<b>0236 010 55</b>						
	M 10	60	<b>0236 010 60</b>	25	<b>0101 10 60</b>	50	<b>0058 10 60</b>	50
		70	<b>0236 010 70</b>		<b>0101 10 70</b>		<b>0058 10 70</b>	
	M 10	75	<b>0236 010 75</b>	50		50	<b>0058 10 80</b>	50
		80	<b>0236 010 80</b>		<b>0101 10 80</b>		<b>0058 10 80</b>	
		90	<b>0236 010 90</b>	25	<b>0101 10 90</b>	50	<b>0058 10 90</b>	50
		100	<b>0236 010 100</b>		<b>0101 10 100</b>		<b>0058 10 100</b>	
110		<b>0236 010 110</b>	<b>0101 10 110</b>					
120		<b>0236 010 120</b>	<b>0101 10 120</b>		<b>0058 10 120</b>			
M 12		40	<b>0236 012 40</b>	25		50	<b>0058 12 50</b>	50
		50	<b>0236 012 50</b>				<b>0058 12 55</b>	
		55					<b>0058 12 55</b>	
		M 12	60	<b>0236 012 60</b>	25	<b>0101 12 60</b>	50	<b>0058 12 60</b>
	70		<b>0236 012 70</b>	<b>0101 12 70</b>		<b>0058 12 70</b>		
	80		<b>0236 012 80</b>	<b>0101 12 80</b>		<b>0058 12 80</b>		
	M 12	90	<b>0236 012 90</b>	50	<b>0101 12 90</b>	50	<b>0058 12 90</b>	50
		100	<b>0236 012 100</b>				<b>0058 12 100</b>	
		120	<b>0236 012 120</b>	25	<b>0101 12 120</b>	50		50
		130			<b>0101 12 130</b>			
140		<b>0236 012 140</b>	25					
M 16	60	<b>0236 016 60</b>	50	<b>0101 16 60</b>	25	<b>0058 16 60</b>	25	
	65	<b>0236 016 65</b>	25					
	70	<b>0236 016 70</b>	50	<b>0101 16 70</b>	25	<b>0058 16 70</b>	25	
	80	<b>0236 016 80</b>		<b>0101 16 80</b>		<b>0058 16 80</b>		
	90	<b>0236 016 90</b>		<b>0101 16 90</b>				
	M 16	100	<b>0236 016 100</b>	25	<b>0101 16 100</b>	25	<b>0058 16 100</b>	25
		120	<b>0236 016 120</b>		<b>0101 16 120</b>		<b>0058 16 120</b>	
		130	<b>0236 016 130</b>		<b>0101 16 130</b>			
		140	<b>0236 016 140</b>					
		150	<b>0236 016 150</b>					
					<b>0101 16 150</b>		25	