


Schraubhaken

mit Schlitz

Stahl verzinkt, blau passiviert


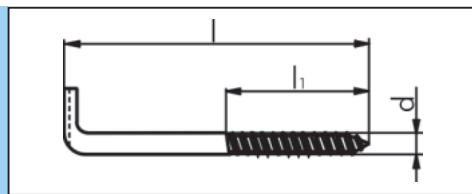


d ₁ mm	l mm	l ₁ mm	Stahl vz., blau pass. Art.-Nr.	VE St.
4,4	30	12	0276 144 30	50
	40	20	0276 144 40	
5,2	50	26	0276 152 50	

d ₁ mm	l mm	l ₁ mm	Stahl vz., blau pass. Art.-Nr.	VE St.
6,0	65	30	0276 16 65	50
	80	40	0276 16 80	
	100	40	0276 16 100	
7,0	125	50	0276 17 125	

mit Bund


Stahl verzinkt, blau passiviert

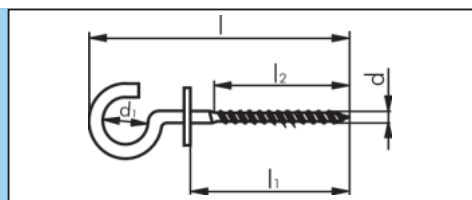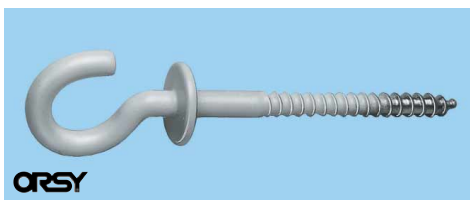

d mm	d ₁ mm	l mm	l ₁ mm	l ₂ mm	Oberfläche	Art.-Nr.	VE/St.
5	14,5	86	54	40	weiß	0234 65 90	100
					verzinkt	0234 65 901	

mit Schlitz und Bund


Stahl verzinkt, blau passiviert

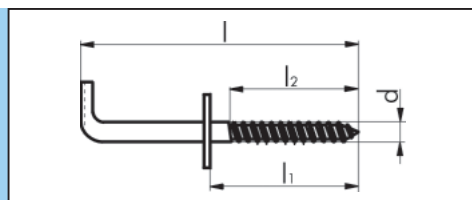

d mm	l mm	l ₁ mm	l ₂ mm	Stahl vz., blau pass. Art.-Nr.	VE/St.
6,0	65	53	30	0276 6 60	50
	80	53	36	0276 6 80	

ohne Bund

Stahl verzinkt, blau passiviert

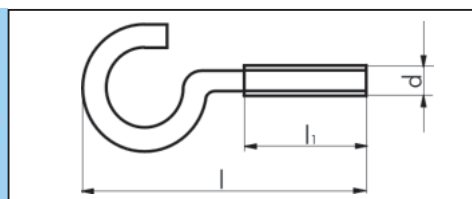

Gew.-Ø d	l mm	l ₁ mm	Stahl vz., blau pass. Art.-Nr.	VE/St.
M4	50	25	0234 74 50	100
M5	60	30	0234 75 60	
M6	60	30	0234 76 60	