 


## VDE-SCHRAUBENDREHER



 
### Innensechskant

- Klinge: brüniert, isoliert
- Abtrieb: DIN 911
- Norm: DIN 7439, IEC 900, EN 60900

1000 V



				Art.-Nr.	VE/St.
	A mm	B/C mm	A inch		
2,5	80	83/27	3 1/8"	<b>0613 635 025</b>	1
3,0	80	83/27	3 1/8"	<b>0613 635 03</b>	1
4,0	75	96/31	3 1/8"	<b>0613 635 04</b>	1
5,0	75	106/35	3 1/8"	<b>0613 635 05</b>	1
6,0	100	106/35	4"	<b>0613 635 06</b>	1
8,0	100	114/38	4"	<b>0613 635 08</b>	1



### AW®-Antrieb

- Klinge: brüniert, isoliert
- Norm: IEC 900, EN 60900

1000 V



				Art.-Nr.	VE/St.
	A mm	B/C mm	A inch		
AW 20	100	106/35	4"	<b>0613 637 20</b>	1
AW 25	100	106/35	4"	<b>0613 637 25</b>	1

### Schraubendreher-Satz für das Elektrohandwerk

- Norm: DIN 7437/7438, IEC 900, EN 60900


1000 V



Art.-Nr. **0613 963 25** VE/St. 1



Art.-Nr. **0613 963 35** VE/St. 1

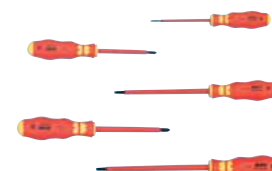

	Art.-Nr.		Art.-Nr.	VE/St.
0,4 x 2,5 x 80	<b>0613 631 025</b>	PH 1	<b>0613 632 1</b>	1
0,8 x 4,0 x 100	<b>0613 631 04</b>	PH 2	<b>0613 632 2</b>	1
1,2 x 6,5 x 150	<b>0613 631 065</b>			1

	Art.-Nr.		Art.-Nr.	VE/St.
0,4 x 2,5 x 80	<b>0613 631 025</b>	PZ 1	<b>0613 633 1</b>	1
0,8 x 4,0 x 100	<b>0613 631 04</b>	PZ 2	<b>0613 633 2</b>	1
1,2 x 6,5 x 150	<b>0613 631 065</b>			1