


## Klavierbandschrauben

- kleiner Senkkopf PZ1

Abmessung in mm	Oberfläche	Antrieb	Art.-Nr.	VE/St.
3 x 10	vermessingt	<b>Z1 (PZD)</b>	<b>0187 3 10</b>	1000
3 x 12			<b>0187 3 12</b>	
3 x 16			<b>0187 3 16</b>	
3 x 20			<b>0187 3 20</b>	
3 x 25			<b>0187 3 25</b>	
3 x 16	brüniert		<b>0187 03 16</b>	
3 x 20			<b>0187 03 20</b>	
3 x 25			<b>0187 03 25</b>	
3 x 12	vernickelt		<b>0187 13 12</b>	
3 x 16			<b>0187 13 16</b>	
3 x 20			<b>0187 13 20</b>	
3 x 25			<b>0187 13 25</b>	
3 x 10	verzinkt, blau pass.		<b>0199 3 10</b>	
3 x 12			<b>0199 3 12</b>	
3 x 16			<b>0199 3 16</b>	
3 x 20		<b>0199 3 20</b>		
3 x 25		<b>0199 3 25</b>		

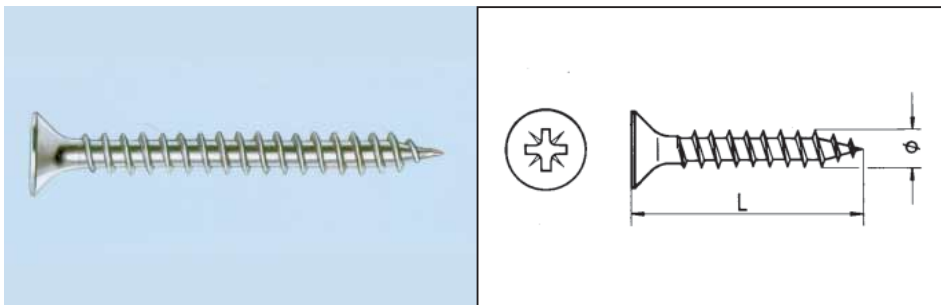

## Wüpfast

- rollensortiert für Automatenverarbeitung

Abmessung in mm	Oberfläche	Antrieb	Art.-Nr.	VE/St.
3,5 x 20	verzinkt, gelb pass.	<b>Z2 (PZD)</b>	<b>0186 835 20</b>	27000
3,5 x 25			<b>0186 835 25</b>	20000
3,5 x 30			<b>0186 835 30</b>	16000
3,5 x 35			<b>0186 835 35</b>	9000
3,5 x 40			<b>0186 835 40</b>	10000