

WINKELSCHRAUBENDREHER INNENSECHSKANT

- Klinge: Sechskantklinge, glanzvernickelt, Stirnkanten gefast, kurze Ausführung
- Abtrieb: ISO 2936 (ähnlich DIN 911)



mm	L1 mm	L2 mm	Art.-Nr.	VE/St.
1,0	45	14	0715 31 59	1/20
1,5	47	16	0715 31 35	1/20
2,0	52	18	0715 31 36	1/20
2,5	56	21	0715 31 37	1/20
3,0	66	23	0715 31 38	1/20
3,5	70	26	0715 31 57	1/10
4,0	74	29	0715 31 39	1/10
4,5	80	31	0715 31 391	1/10
5,0	85	33	0715 31 40	1/10
5,5	90	35	0715 31 401	1/10
6,0	96	38	0715 31 41	1/10
7,0	102	41	0715 31 42	1/10
8,0	108	44	0715 31 43	1/10
9,0	114	47	0715 31 44	1/10
10,0	122	50	0715 31 45	1
11,0	129	53	0715 31 46	1
12,0	137	57	0715 31 47	1
14,0	154	70	0715 31 48	1
16,0	168	73	0715 31 481	1
17,0	177	80	0715 31 49	1
19,0	199	89	0715 31 50	1
22,0	222	102	0715 31 51	1


- Klinge: Sechskantklinge, glanzvernickelt, Stirnkanten gefast, lange Ausführung
- Abtrieb: ISO 2936L (ähnlich DIN 911)



mm	L1 mm	L2 mm	Art.-Nr.	VE/St.
2,0	102	18	0715 31 17	1/10
2,5	115	21	0715 31 18	1/10
3,0	129	23	0715 31 19	1/10
3,5	140	26	0715 31 58	1/10
4,0	144	29	0715 31 20	1/10
5,0	165	33	0715 31 21	1/10
6,0	186	38	0715 31 22	1/10
7,0	197	41	0715 31 23	1/10
8,0	208	44	0715 31 24	1/10
9,0	219	47	0715 31 25	1/10
10,0	234	50	0715 31 26	1/10
12,0	262	57	0715 31 28	1/5
14,0	294	70	0715 31 29	1/5
17,0	337	80	0715 31 30	1/5

WINKELSCHRAUBENDREHER-SATZ

Im Kunststoffhalter, kurze Ausführung

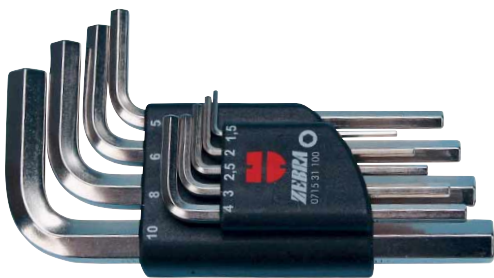

Set	Inhalt mm	Art.-Nr.	VE/St.
9-tlg.	1,5, 2, 2,5, 3, 4, 5, 6, 8, 10	0715 31 100	1
10-tlg.	1,5, 2, 2,5, 3, 4, 5, 6, 8, 10, 12	0715 31 110	1
14-tlg.	2, 3, 4, 5, 6, 7, 8, 9, 10, 11, 12, 14, 17, 19	0715 31 54*	1


* Lieferung in einer Plastiktasche.

Am Ring, kurze Ausführung



Set	Inhalt mm	Art.-Nr.	VE/St.
8-tlg.	2, 2,5, 3, 4, 5, 6, 8, 10	0715 31 55	1

Im Kunststoffhalter, lange Ausführung

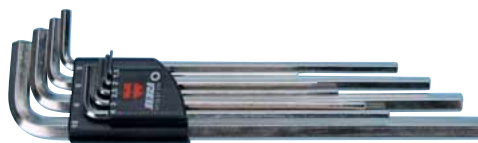

Set	Inhalt mm	Art.-Nr.	VE/St.
9-tlg.	1,5, 2, 2,5, 3, 4, 5, 6, 8, 10	0715 31 120	1