


BLINDNIETE

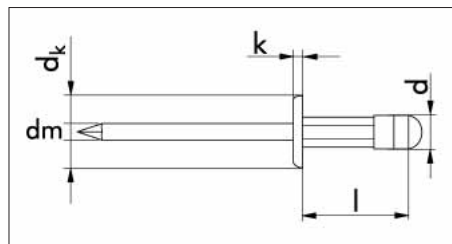


Flachrundkopf

Hülse: Aluminium
Dorn: Edelstahl A2


Mittelfester Nietbereich

d x l mm	Bohrloch-Ø mm	Klemmbereich mm	d _k mm	k mm	dm mm	Scherbruchlast N	Zugbruchlast N	Art.-Nr.	VE St.
3,2 x 8,0	3,3-3,5	0,5- 5,0	6,2	1,1	1,8	700	980	0914 32 48	500
3,2 x 11,0		4,0- 8,0						0914 32 64	
4,0 x 10,0	4,1-4,3	1,2- 6,3	8,0	1,4	2,2	1200	2400	0914 40 64	
4,0 x 13,0		4,0- 9,6						0914 40 96	
4,0 x 17,0		6,4-12,7						0914 40 127	
4,8 x 10,0	4,9-5,1	1,5- 6,5	9,9	1,6	2,7	1470	2400	0914 48 64	
4,8 x 15,0		4,5-11,0						0914 48 110	
4,8 x 25,0		12,5-20,0						0914 48 198	

ORSY®-lagerfähig

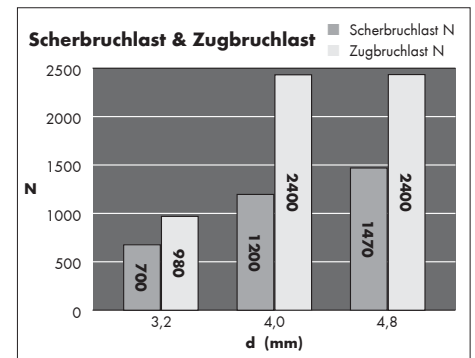

BLINDNIETE

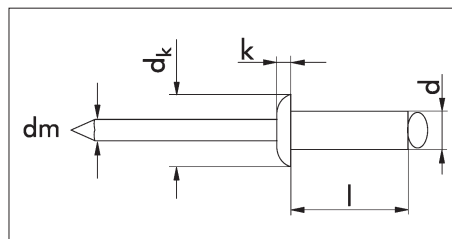

Flachrundkopf

Hülse: Aluminium,
braun eloxiert
Dorn: Edelstahl A2

d x l mm	Bohrloch-Ø mm	Klemmbereich mm	d _k mm	k mm	dm mm	Scherbruchlast N	Zugbruchlast N	Art.-Nr.	VE St.
4,0 x 10	4,1-4,3	1,2-6,3	8,0	1,4	2,2	1150	1630	0915 740 64	500
4,0 x 13		4,0-9,6						0915 740 96	

ORSY®-lagerfähig

