



## Montagezubehör für Zentralschmierteile

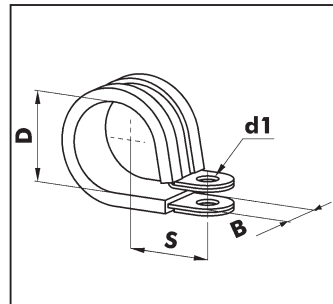

### Rohr- und Halterungsschelle „Multifix“ mit Gummiprofil

D* mm	Breite B mm	Loch-Ø d1 mm	S mm	Art.-Nr.	VE/St.	VE/St. Sorti- ment	
6	12	M5	8,0 + D/2	<b>0542 6 12</b>	50/100	10	
8				<b>0542 8 12</b>			
10				<b>0542 10 12</b>			
12	15	M6	11,2 + D/2	<b>0542 12 15</b>	50	5	
15				<b>0542 15 15</b>			
18				<b>0542 18 15</b>			
20				<b>0542 20 15</b>			
22				<b>0542 22 15</b>			
25				<b>0542 25 15</b>			
30	<b>0542 30 15</b>	5					
15	20		M8	14,5 + D/2	<b>0542 15 20</b>	25	4
20					<b>0542 20 20</b>		
25		<b>0542 25 20</b>					


\* Innendurchmesser Schelle/Außendurchmesser Rohr

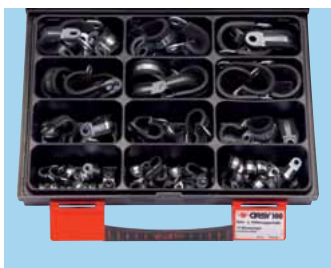

### Multifix-Sortiment


Inhalt: 12 Abmessungen,  
73 Teile (siehe Spalte  
VE/Sortiment)

Art.-Nr. **0964 542**  
VE/St. 1

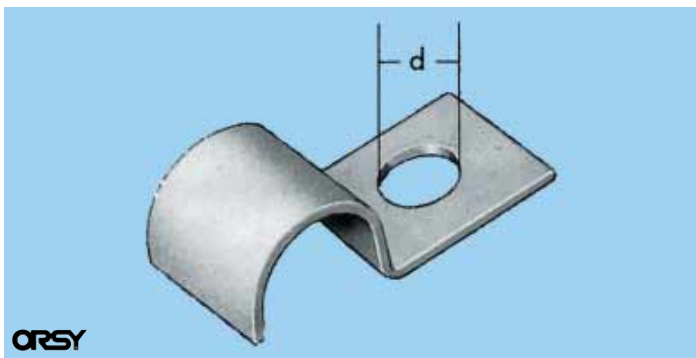

### Kabelschellen DIN 72571

Ø mm	d mm	Breite mm	Material- stärke mm	Art.-Nr.	VE/St.
4	4,8	10	1,0	<b>0592 4</b>	100
6				<b>0592 6</b>	100/300
8				<b>0592 8</b>	

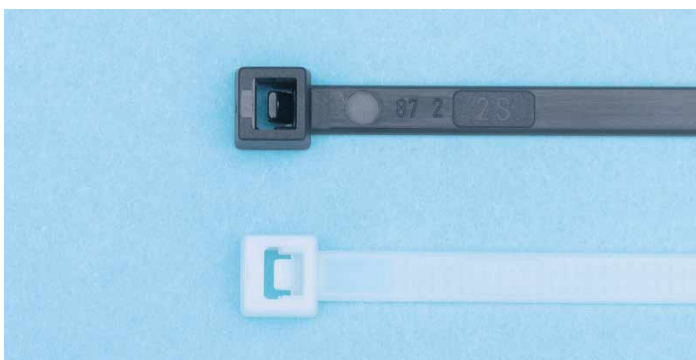

### Kabelbänder

mit Metall- und Kunststoffzungenverschluss  
Farbe: schwarz

Breite mm	Länge mm	Bündelungs-Ø mm	Art.-Nr.	VE/St.
3,5	200	1,6- 40	<b>0502 131</b>	100/1000
4,8	280	1,6- 75	<b>0502 151</b>	100/300
7,8	360	1,6-100	<b>0502 181</b>	100



### Wickelschlauch

Farbe: schwarz

Innen-Ø mm	Bündel-Ø mm	Wand- stärke mm	Wendel- breite mm	Art.-Nr.	VE/m
3,7	4,0- 20,0	0,65	7,0	<b>0771 00 40</b>	25
8,2	12,0- 50,0	0,90	12,0	<b>0771 00 80</b>	
17,6	20,0-120,0	1,20	22,0	<b>0771 00 90</b>	