
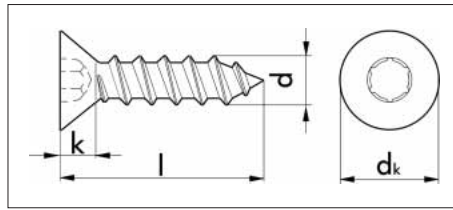


BLECHSCHRAUBE SENKKOPF

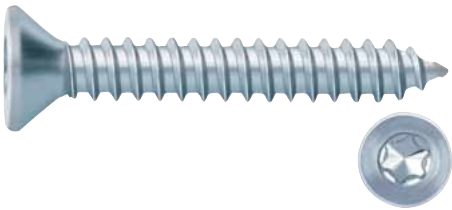

mit AW-Antrieb

nach WN 112
Form C, mit Spitze

Stahl verzinkt,
blau passiviert (A2K)

Edelstahl A2

Nenn-Ø d mm	3,5	3,9	4,2	4,8
Kopf-Ø d _k mm	6,8	7,5	8,1	9,5
Kopfhöhe k mm	2,5	2,8	3,1	3,3
Antrieb	AW 10	AW 20	AW 20	AW 25

Nenn-Ø d mm	Länge l mm	Stahl verzinkt, blau passiviert Art.-Nr.	VE/St.	Edelstahl A2 Art.-Nr.	VE/St.
3,5	9,5	0112 535 95	250/1000		250/1000
	13	0112 535 13		0123 935 13	
	16	0112 535 16		0123 935 16	
	19	0112 535 19		0123 935 19	
3,9	9,5		250/1000	0123 939 95	1000
	13	0112 539 13		0123 939 13	250/1000
	16	0112 539 16		0123 939 16	
	19	0112 539 19		0123 939 19	
	25	0112 539 25		0123 939 25	
	38	0112 539 38	0123 939 38		
4,2	13	0112 542 13	250/1000		250/1000
	16	0112 542 16		0123 942 16	
	19	0112 542 19		0123 942 19	
	25	0112 542 25		0123 942 25	100/1000
	32			0123 942 32	
	38			0123 942 38	
	50		0123 942 50		
4,8	16	0112 548 16	100/1000	0123 948 16	100/1000
	19	0112 548 19		0123 948 19	
	25	0112 548 25		0123 948 25	
	32	0112 548 32	100/500	0123 948 32	100/500
	38	0112 548 38		0123 948 38	
	50	0112 548 50	100	0123 948 50	100
	60	0112 548 60		0123 948 60	
	70	0112 548 70		0123 948 70	
	80			0123 948 80	
		90		0123 948 90	
	100		0123 948 100		

ORSY®-lagerfähig

Sortimente ORSY 100



Art.-Nr. 0964 112 5

Inhalt: 1400 Blechschrauben und 3 Bits (AW10/AW20/AW25)

0112 535 95/13/16

0112 539 13/16/19/25/38

0112 542 16/25

0112 548 16/19/25/32/38/50

Art.-Nr. 0964 123 9

Inhalt: 1350 Blechschrauben und 3 Bits (AW10/AW20/AW25)

0123 935 13/16/19

0123 939 13/16/19/25/38

0123 942 16/19/25/32/38/50

0123 948 25/32