


SCHEIBEN

ISO 7089

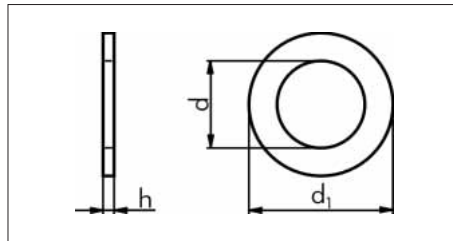

300 HV


Stahl verzinkt, blau passiviert
(A2K)

Für Gewinde-Ø	Außen-Ø d mm	Innen-Ø d ₁ mm	Stärke s mm	Stahl verzinkt, blau passiviert (A2K) Art.-Nr.	VE/St.
M8	16	8,4	1,6	5149 988	200
M10	20	10,5	2	5149 981 0	
M12	24	13	2,5	5149 981 2	
M16	30	17	3	5149 981 6	100
M20	37	21	3	5149 982 0	
M24	44	25	4	5149 982 4	
M30	56	31	4	5149 983 0	50
M36	66	37	5	5149 983 6	

ORSY®-lagerfähig

SCHEIBEN

ISO 7090

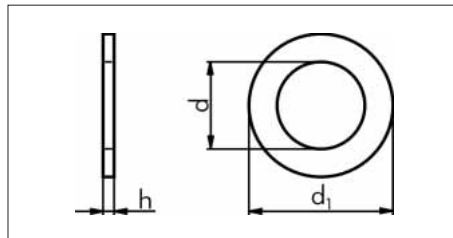

300 HV

Stahl verzinkt, blau passiviert
(A2K)

Für Gewinde-Ø	Außen-Ø d mm	Innen-Ø d ₁ mm	Stärke s mm	Stahl verzinkt, blau passiviert (A2K) Art.-Nr.	VE/St.
M8	16	8,4	1,6	5149 998	500
M10	20	10,5	2	5149 991 0	200
M12	24	13	2,5	5149 991 2	
M16	30	17	3	5149 991 6	
M20	37	21	3	5149 992 0	100
M24	44	25	4	5149 992 4	
M27	50	28	4	5149 992 7	
M30	56	31	4	5149 993 0	50
M33	60	34	5	5149 993 3	
M36	66	37	5	5149 993 6	

ORSY®-lagerfähig