


## GEWINDESTANGE



**DIN 976-1 (Form A) mit  
metrischem ISO-Regelgewinde,  
Edelstahl A2**

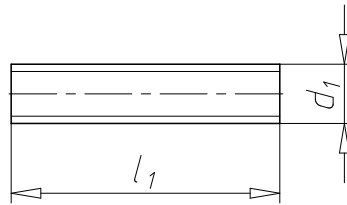

Gewindeart x Nenndurchmesser (d <sub>1</sub> )	Länge (l <sub>1</sub> )	Festigkeitsklasse	Art.-Nr.	VE
M14	1000 mm	70	<b>0954 14</b>	1/10
M14	2000 mm	70	<b>0954 002 14</b>	5
M14	3000 mm	70	<b>0954 003 14</b>	1
M16	1000 mm	70	<b>0954 16</b>	1/10
M16	2000 mm	70	<b>0954 002 16</b>	1
M16	3000 mm	70	<b>0954 003 16</b>	1
M18	1000 mm	70	<b>0954 18</b>	1/10
M18	2000 mm	70	<b>0954 002 18</b>	1
M20	1000 mm	70	<b>0954 20</b>	1/10
M20	2000 mm	70	<b>0954 002 20</b>	1
M20	3000 mm	70	<b>0954 003 20</b>	1
M22	1000 mm	70	<b>0954 22</b>	1/5
M24	1000 mm	70	<b>0954 24</b>	1/5
M24	2000 mm	70	<b>0954 002 24</b>	1
M24	3000 mm	70	<b>0954 003 24</b>	1
M27	1000 mm	50	<b>0954 27</b>	1
M27	2000 mm	50	<b>0954 002 27</b>	1
M27	3000 mm	50	<b>0954 003 27</b>	1
M30	1000 mm	50	<b>0954 30</b>	1
M30	2000 mm	50	<b>0954 002 30</b>	1
M30	3000 mm	50	<b>0954 003 30</b>	1
M33	2000 mm	50	<b>0954 002 33</b>	1
M33	3000 mm	50	<b>0954 003 33</b>	1
M36	1000 mm	50	<b>0954 36</b>	1
M36	3000 mm	50	<b>0954 003 36</b>	10
M39	1000 mm	50	<b>0954 39</b>	1
M42	1000 mm	50	<b>0954 42</b>	1