


THREADED MANDREL

For rivet nut pliers
Art. No. 0971 1

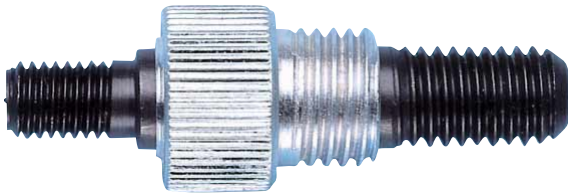

For nominal dia.	Threaded Mandrel with mouth piece for rivet nuts with small countersunk head Pre-No. 0917	Threaded mandrel with mouth piece for all rivet nuts Pre-No. 0948
	Art. No.	Art. No.
M3	0917 13	0917 948 3
M4	0917 14	0917 948 4
M5	0917 15	0917 948 5
M6	0917 16	0917 948 6
M8	0917 18 *	0917 948 8 *

* Attention! Please note:

The use of M8 threaded mandrels is limited to the specified rivet nuts.

Before using non-Würth rivet nuts, you must conduct your own tests.

Art. No.	Description	Material	Suitable	Matching threaded mandrel
0948 200 8	Rivet Nuts with truss head	Aluminum	Yes	0917 948 8
0948 220 8	Rivet Nuts with truss head	Aluminum	Yes	0917 948 8
0948 320 8	Rivet Nuts with countersunk head	Aluminum	Yes	0917 948 8
0948 420 8	Rivet Nuts with countersunk head	Aluminum	Yes	0917 948 8
0917 80	ZEBRA® Rivet Nuts with countersink flanging	Steel	Yes	0917 18
0917 780	ZEBRA® Rivet Nuts with countersink flanging and shaft knurling	Steel	Yes	0917 948 8
0942 18	ZEBRA® Rivet Nuts with countersunk head	Stainless steel	Yes	0917 948 8