


Hexagon Sheet Metal Screws

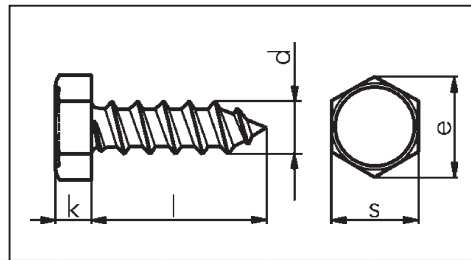

ORSY

Nominal dia. d	in mm	3.5	3.9	4.2	4.8	5.5	6.3	8
Head height k	mm	2.3	2.3	2.8	3.0	4.0	4.8	5.8
e in mm		5.96	7.59	8.71	8.71	10.95	14.26	
s in mm		5.5	7	8	8	10	13	

DIN 7976 (ISO 1479)

Shape C, with tip

Galvanized steel, blue passivated (A2K)
A2

Nominal Dia. d in mm	length l in mm	Galv. steel blue pass. Art. No.	P.Qty.	A2 Art. No.	P. Qty.
3.5	6.5	0114 35 65	3500		
	9.5	0114 35 95	100	0122 35 95	1000
	13			0122 35 13	
	16			0122 35 16	
	19	0114 35 19	1000	0122 35 19	
	22			0122 35 22	500
	25			0122 35 25	
	32			0122 35 32	
	38			0122 35 38	
	45			0122 35 45	
50			0122 35 50		
3.9	6.5	0114 39 65	1000		
	9.5	0114 39 95		0122 39 95	1000
	13	0114 39 13	100	0122 39 13	
	16			0122 39 16	
	19	0114 39 19		0122 39 19	
	22			0122 39 22	500
	25			0122 39 25	
	32			0122 39 32	
	38			0122 39 38	
	45			0122 39 45	
50			0122 39 50		
4.2	9.5	0114 42 95	100	0122 42 95	1000
	13	0114 42 13		0122 42 13	
	16	0114 42 16		0122 42 16	
	19	0114 42 19		0122 42 19	
	22	0114 42 22		0122 42 22	
	25		0122 42 25	500	
	32		0122 42 32		
	38		0122 42 38		
	45		0122 42 45		
	50		0122 42 50		
	60		0122 42 60		
	70		0122 42 70		
	4.8	9.5	0114 48 95		2500
13		0114 48 13	100	0122 48 13	1000
16		0114 48 16		0122 48 16	
19		0114 48 19		0122 48 19	100
22		0114 48 22		0122 48 22	1000
25		0114 48 25		0122 48 25	1000
32		0114 48 32		0122 48 32	500
38				0122 48 38	200
45				0122 48 45	250
50				0122 48 50	
55				0122 48 55	
60		0114 48 60	1000	0122 48 60	200
70				0122 48 70	
80				0122 48 80	
90			0122 48 90		
100			0122 48 100		
110			0122 48 110		

ORSY 100 Assortment



Includes: 890 sheet-metal screws, DIN 7976, Galvanized steel, blue passivated (A2K) and combination sheet metal screws with captive washer, galvanized steel, blue passivated (A2K)

- 0114 48 13/19/25
- 0114 63 16/19/22/25/32
- 0114 8 19/25
- 0129 085 5 13/16
- 0129 086 3 16/20
- 0129 086 5 16
- 0129 088 0 19

Art. No. 0964 129 01