

Sheet Metal Screws

with flat head and collar
Steel, Delta Seal black

- For attaching soft materials (e.g. plastic) inside motor vehicles, e.g. dashboard, interior cladding etc.

l mm	Dia. 3.9 mm Art. No.	P. Qty.	Dia. 4.2 mm Art. No.	P. Qty.	Dia. 4.8 mm Art. No.	P. Qty.
9.5	0134 039 95	100/300	0134 042 95	100/300	0134 048 95	100/300
13	0134 039 13	100	0134 042 13		0134 048 13	
16	0134 039 16		0134 042 16		0134 048 16	
19	0134 039 19		0134 042 19		0134 048 19	
22	0134 039 22	100/300	0134 042 22		0134 048 22	
25	0134 039 25	100	0134 042 25	0134 048 25		
32	0134 039 32		0134 042 32	0134 048 32		
38	0134 039 38		0134 042 38	0134 048 38		

Nom. dia. d in mm	3.9	4.2	4.8
d _k in mm	10.0	11.0	12.0
t in mm	1.0	1.2	1.2
Drive	H2	H2	H2

ORSY100 Assortments

Sheet Metal Screws, steel Delta Seal black, 1500 pieces:


0134 039 95/13/16/19/22/25
0134 042 95/13/16/19/22/25
0134 048 95/13/16/19/22/25

Art. No. 0964 134 0

800 pieces:

0134 042 13/16/19/25
0134 048 13/16/19/25

Art. No. 0964 134 3

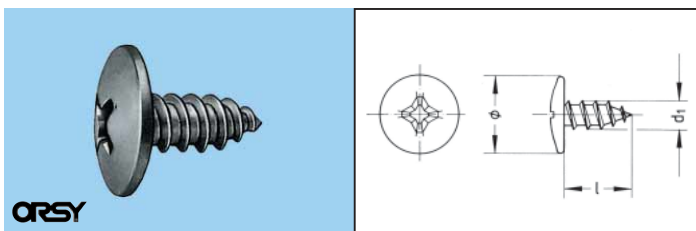


Special Sheet Metal Screws

Galvanized steel, blue passivated (A2K)

- With flat head and wide edge.
- For various Opel models (under window frames and decorative window sills).


d ₁ in mm	l in mm	Head dia. in mm	Acc. to Opel Orig. No.	Galv. steel, blue pass. Art. No.	P. Qty.
4.2	9.5	11	03440109	0126 42 95	100/1000
	12.5		03457561	0126 42 125	
	19		-	0126 42 19	

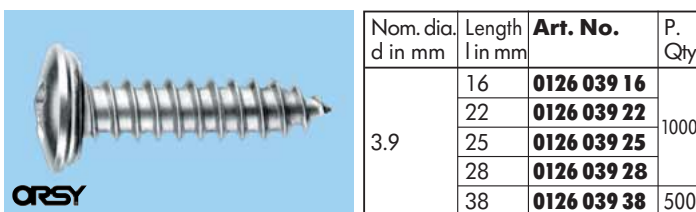

Sheet Metal Screws

Galvanized steel, blue passivated (A2K) with Phillips head, drive: PZ 2

- Tallow-drop head (especially for cover caps, see below).
- Tapping screw thread pursuant to EN ISO 1478.

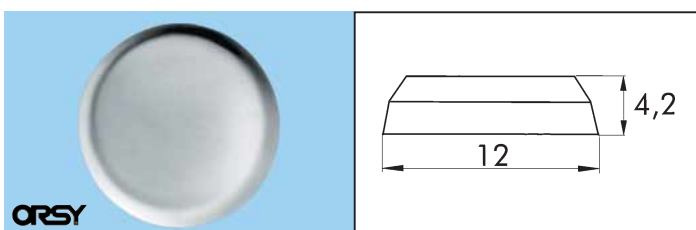

Cover Caps

- For Sheet Metal Screws, Art. No. 0126 039 ... /0115 003 9..
- For A2 Window Sill Screws, Art. No. 0126 2..
- For *pias* Window Sill Screws, Art. No. 0211 724 220
- Material: polyethylene.

Color	Art. No.	P. Qty.
Pure white RAL 9010	0590 12 125	100/500
Silver gray RAL 7001	0590 125 125	
Jet black RAL 9005	0590 126 125	
Mahogany brown RAL 8016	0590 128 125	