

HAND-HELD RIVETING PLIERS



Art. No. 091512

P. Qty. 1

For installing blind rivets dia. 2.4 mm, 3 mm and 4 mm made of aluminum, copper, steel and stainless steel and aluminum blind rivets dia. 5 mm.

Technical data:

Weight: 590 g, total length: 260 mm.

Mouthpieces for	Art. No.
2.4 mm aluminum blind rivets, hole dia. mouthpiece: 1.7 mm	0946 10 18
3.0 mm / 3.2 mm aluminum blind rivets, A2 blind rivets, hole dia. mouthpiece: 2.3 mm	0946 10 24
4.0 aluminum, copper rivet (mouthpiece length 7.5 mm)	
4 mm / Qty. A2 blind rivets, hole dia. mouthpiece: 2.9 mm	0946 10 29
5 mm aluminum alloy blind rivets, hole dia. mouthpiece: 3.2 mm	0946 10 32
Replacement Clamping Jaws	0946 10



Art. No. 091511

P. Qty. 1

For installing blind rivets dia. 3.2 mm, 4 mm, 4.8 mm made of aluminum, copper, steel and stainless steel.


Particularly suited for hollow profiles.

Technical data:

Length, mouthpiece mounting incl. mouthpiece: 52 mm.

Diameter, mouthpiece mounting: 19 mm.

Mouthpieces for	Art. No.
4.0 mm blind rivets, hole dia. mouthpiece: 2.2 mm	0915 140
4.8 mm blind rivets, hole dia. mouthpiece: 3.3 mm	0915 150
Replacement Clamping Jaws	0946 10

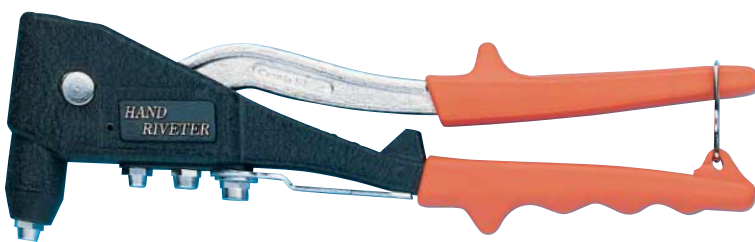

Art. No. 0949 15

P. Qty. 1

For installing blind rivets dia. 2.4 mm, 3 mm and 4 mm made of aluminum, copper, steel and stainless steel and aluminum blind rivets dia. 5 mm.

Technical data:

Weight: 590 g, total length: 260 mm.

Mouthpieces for	Art. No.
2.4 mm aluminum blind rivets, hole dia. mouthpiece: 1.7 mm	0946 10 18
3.0 mm / 3.2 mm aluminum, steel, A2 blind rivets, hole dia. mouthpiece: 2.3 mm	0946 10 24
4.0 aluminum, copper rivet (mouthpiece length 7.5 mm)	
4 mm / Qty. A2 blind rivets, hole dia. mouthpiece: 2.9 mm	0946 10 29
5 mm aluminum alloy blind rivets, hole dia. mouthpiece: 3.2 mm	0946 10 32
Replacement Clamping Jaws	0946 10