


## 3/8" Sockets for Outer TX Screws


Finish: chrome-plated, polished/matte  
 Input drive: 3/8", ball groove  
 Output drive: outer TX  
 Type: short  
<sup>1</sup> Type: long

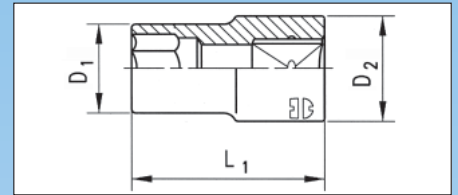

	mm	L <sub>1</sub> mm	D <sub>1</sub> mm	D <sub>2</sub> mm	Art. No.	
5	4.75	26	7.0	17	0715 122 05	1
6	5.74	26	7.7	17	0715 122 06	
7	6.22	26	8.3	17	0715 122 07	
8	7.52	26	10.2	17	0715 122 08	
10	9.42	26	12.3	17	0715 122 10	
11	10.08	26	13.3	17	0715 122 11	
12	11.17	26	14.3	17	0715 122 12	
14	12.9	26	15.8	17	0715 122 14	
8 <sup>1</sup>	7.52	55	9.9	17	0715 122 081	

## 3/8" Screwdriver Inserts


Finish: chrome-plated, polished/matte  
 Input drive: 3/8", ball groove  
 Output drive: inner TX  
 Type: short

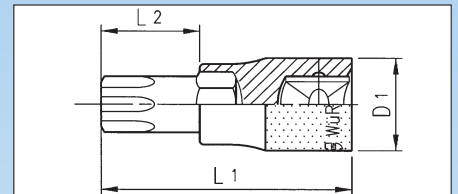

	mm	L <sub>1</sub> mm	L <sub>2</sub> mm	D <sub>1</sub> mm	Art. No.	
15	3.26	50.5	20.5	19	0715 123 15	1
20	3.84	50.5	20.5	19	0715 123 20	
25	4.40	50.5	20.5	19	0715 123 25	
27	4.96	50.5	20.5	19	0715 123 27	
30	5.49	50.5	20.5	19	0715 123 30	
40	6.66	50.5	20.5	19	0715 123 40	
45	7.77	50.5	20.5	19	0715 123 45	
50	8.79	50.5	20.5	19	0715 123 50	

## 3/8" Universal Joint


Finish: chrome-plated, polished  
 Input drive: 3/8", ball groove  
 Output drive: outer TX  
 Type: short

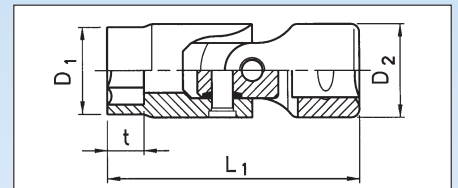

	L <sub>1</sub> mm	D <sub>1</sub> mm	D <sub>2</sub> mm	t mm	Art. No.	
8	46	9.9	19	6.6	0715 126 08	1
10	47	11.8	19	7.4	0715 126 10	
12	48.5	14.5	19	9	0715 126 12	
14	49	15.7	19	9.8	0715 126 14	

## 3/8" Clamping Rail

Finis: high-gloss chrome-plated, with mounting hole  
 Application:  
 16 clamps for easy storage of 3/8"-sockets

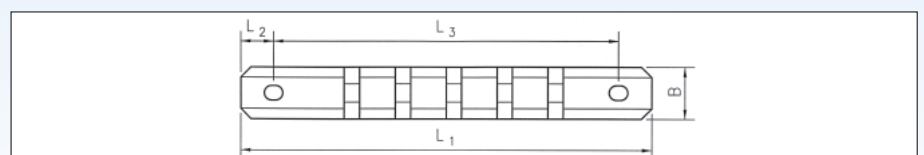

L <sub>1</sub> mm	L <sub>2</sub> mm	L <sub>3</sub> mm	B mm	D mm	Art. No.	
430	13	407	20	5.5	0713 121 01	1