


NEOPRENE RIVET NUTS

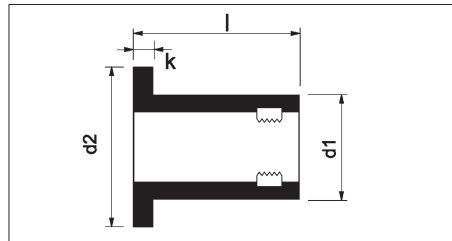

Round pan head

Detachable, electrically insulating rivet connection with vibration and noise-damping function for fastening metal and plastic connections.


Material:

Rivet body in neoprene (EPDM) with brass insert
Hardness: 60 Shore

- Installation in blind or pocket holes
- Dual function as thread carrier or fastener
- Air and moisture-tight connection
- Ideal for various materials
- Possible installation temperatures: -30°C to +80°C
- Ozone-resistant

t	Drill hole dia. max. mm	Clamping range in mm	d2 mm +/- 0.5/0.8	l mm	d1 mm	Head height k mm	Tightening torque in Nm	Art. no.	P. Qty.
M3	8.3	0.4-4.0	11.0	12.6	7.9	≤ 1.4	0.25-0.50	0948 75 3	100
M4								0948 75 4	
M5	9.9	0.4-4.9 4.0-11.6	12.5 14.0	14.1 21.5	9.6	≤ 0.9	0.35-0.50 0.30-0.90	0948 75 5	
								0948 75 50	
M6	13.0	0.8-4.7 6.4-11.5	19.0 16.0	21.1 26.7	12.7	≤ 4.8 ≤ 2.0	0.80-1.00	0948 75 6	
								0948 75 60	
M8	16.2	0.4-4.0 3.9-9.5	22.0	18.3 27.9	15.9	≤ 3.2 ≤ 5.7	1.00-1.50	0948 75 8	
								0948 75 80	

Can be stored in ORSY® system

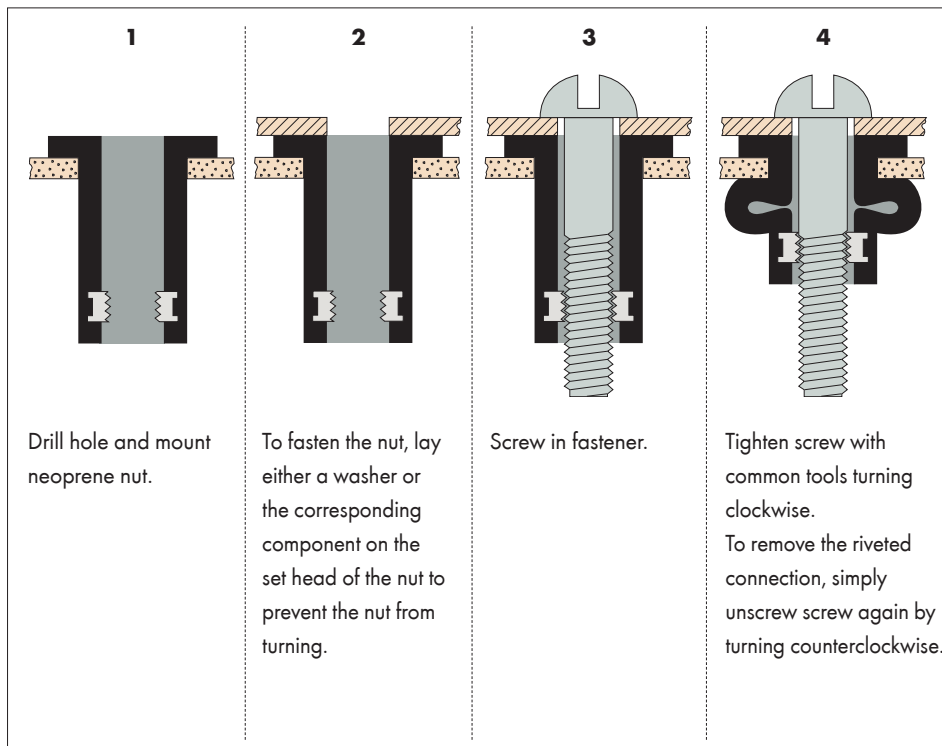

Fields of application:

Electronics construction, vehicle construction, trailer construction, sign-making, steel construction, system construction, air-conditioning and refrigeration engineering, agricultural engineering.