



GALVANIZED STEEL HEXAGONAL SPACER SLEEVE

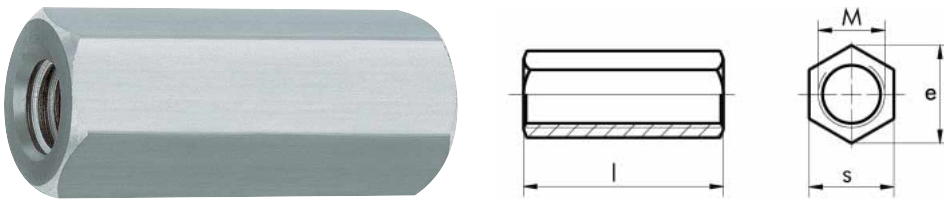

Material	Thread type x nominal diameter (M)	Length (l)	Wrench size (s)	Corner dimension (e)	Strength class	Art. No.	P.
Steel	M6	20 mm	10 mm	11.05 mm	4	0974 6 20	100
Steel	M6	25 mm	10 mm	11.05 mm	4	0974 6 25	50
Steel	M6	30 mm	10 mm	11.05 mm	4	0974 6 30	50
Steel	M6	50 mm	10 mm	11.05 mm	4	0974 6 50	500
Steel	M8	20 mm	11 mm	12.16 mm	4	0974 8 20	100
Steel	M8	25 mm	11 mm	12.16 mm	4	0974 8 25	100
Steel	M8	30 mm	11 mm	12.16 mm	4	0974 8 30	50
Steel	M10	20 mm	13 mm	14.38 mm	4	0974 10 20	50
Steel	M10	25 mm	13 mm	14.38 mm	4	0974 10 25	50
Steel	M10	30 mm	13 mm	14.38 mm	4	0974 10 30	50
Steel	M10	40 mm	13 mm	14.38 mm	4	0974 10 40	50
Steel	M12	40 mm	17 mm	18.9 mm	4	0974 12 40	50
Steel	M12	50 mm	17 mm	18.9 mm	4	0974 12 50	50
Steel	M16	40 mm	24 mm	26.75 mm	4	0974 16 40	10
Steel	M20	50 mm	30 mm	32.95 mm	4	0974 20 50	10

Suitable for ORSY storage

STAINLESS-STEEL A2 HEXAGONAL SPACER SLEEVE

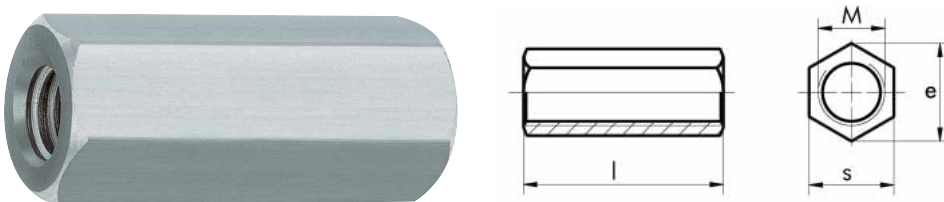

Art. No.	0865 520 630	0865 520 830	0865 521 030	0865 521 240	0865 521 650
P.	100	100	100	50	25
Material	stainless steel A2	stainless steel A2	stainless steel A2	stainless steel A2	stainless steel A2
Thread type x nominal diameter (M)	M6	M8	M10	M12	M16
Length (l)	30 mm	30 mm	30 mm	40 mm	50 mm
Wrench size (s)	10 mm	13 mm	17 mm	19 mm	24 mm
Corner dimension (e)	11.05 mm	14.38 mm	18.9 mm	21.1 mm	26.75 mm

Storable in ORSY