


FLAT WASHER FOR HEXAGON BOLTS AND NUTS

DIN 125 galvanised steel, blue passivated (A2K)

Norms	DIN 125
Material	Steel
Vickers hardness, HV	140 HV
Surface	Galvanised
RoHS-compliant	Yes

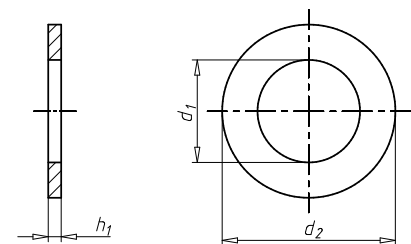

Suitable for screw thread	Internal diameter (d ₁)	Outer diameter (d ₂)	Thickness (h ₁)	Form	Art. No.	P. Qty.
M1.6	1.7 mm	4 mm	0.3 mm	A	0407 17	5000
M2	2.2 mm	5 mm	0.3 mm	A	0407 2	1000/10000
M2	2.7 mm	6 mm	0.5 mm	B	0407 992 5	5000
M2.3	2.5 mm	6 mm	0.5 mm	A	0407 25	500/10000
M2.5	2.7 mm	6 mm	0.5 mm	A	0407 27	100/1000/10000
M3	3.2 mm	7 mm	0.5 mm	A	0407 3	500/1000/10000
M3	3.2 mm	7 mm	0.5 mm	B	0407 993	10000
M3.5	3.7 mm	8 mm	0.5 mm	A	0407 37	100/10000
M4	4.3 mm	9 mm	0.8 mm	A	0407 4	250/500/1000/10000
M4	4.3 mm	9 mm	0.8 mm	B	0407 994	10000
M5	5.3 mm	10 mm	1 mm	A	0407 5	250/500/1000/10000
M5	5.3 mm	10 mm	1 mm	B	0407 995	5000
M6	6.4 mm	12 mm	1.6 mm	A	0407 6	250/500/1000/5000
M6	6.4 mm	12 mm	1.6 mm	B	0407 996	2500
M7	7.4 mm	14 mm	1.6 mm	A	0407 7	500/2000
M7	7.4 mm	14 mm	1.6 mm	B	0407 997	1000
M8	8.4 mm	16 mm	1.6 mm	A	0407 8	250/1000/2000
M8	8.4 mm	16 mm	1.6 mm	B	0407 998	2000
M10	10.5 mm	20 mm	2 mm	B	0407 991 0	1000
M10	10.5 mm	20 mm	2.0 mm	A	0407 10	100/500/1000
M12	13 mm	24 mm	2.5 mm	A	0407 12	100/500/1000
M12	13 mm	24 mm	2.5 mm	B	0407 991 2	500
M14	15 mm	28 mm	2.5 mm	A	0407 14	100/500
M14	15 mm	28 mm	2.5 mm	B	0407 991 4	500
M16	17 mm	30 mm	3 mm	A	0407 16	100/500
M16	17 mm	30 mm	3 mm	B	0407 991 6	500
M18	19 mm	34 mm	3 mm	A	0407 991 8	250
M18	19 mm	34 mm	3 mm	B	0407 18	100/250/300
M20	21 mm	37 mm	3 mm	A	0407 992 0	200
M20	21 mm	37 mm	3 mm	B	0407 20	100/200/300
M22	23 mm	39 mm	3 mm	A	0407 992 2	200
M22	23 mm	39 mm	3 mm	B	0407 22	100/200
M24	25 mm	44 mm	4 mm	A	0407 992 4	100
M24	25 mm	44 mm	4 mm	B	0407 24	100/200
M26	27 mm	50 mm	4 mm	B	0407 26	100
M27	28 mm	50 mm	4 mm	A	0407 992 7	100
M28	29 mm	50 mm	4 mm	B	0407 28	100
M30	31 mm	56 mm	4 mm	A	0407 993 0	50
M30	31 mm	56 mm	4 mm	B	0407 30	50
M32	33 mm	60 mm	5 mm	A	0407 993 2	100
M32	33 mm	60 mm	5 mm	B	0407 32	50/100
M33	34 mm	60 mm	5 mm	A	0407 993 3	50
M33	34 mm	60 mm	5 mm	B	0407 33	25/50