


HEXAGONAL BOLT WITH THREAD UP TO THE HEAD

ISO 4017, stainless steel A2-50 and A2-70, plain

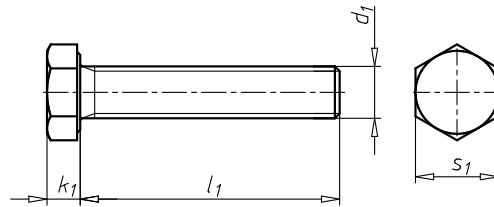

Thread type x nominal diameter (d ₁)	Length (l ₁)	Head height (k ₁)	External drive (s ₁)	Property class	Product class	Art. No.	P. Qty.
M4	5 mm	2.8 mm	WS7	70	A	0096 4 5	1000
M4	6 mm	2.8 mm	WS7	70	A	0096 4 6	1000
M4	8 mm	2.8 mm	WS7	70	A	0096 4 8	1000
M4	10 mm	2.8 mm	WS7	70	A	0096 4 10	200
M4	12 mm	2.8 mm	WS7	70	A	0096 4 12	200
M4	14 mm	2.8 mm	WS7	70	A	0096 4 14	1000
M4	16 mm	2.8 mm	WS7	70	A	0096 4 16	200
M4	18 mm	2.8 mm	WS7	70	A	0096 4 18	200
M4	20 mm	2.8 mm	WS7	70	A	0096 4 20	200
M4	22 mm	2.8 mm	WS7	70	A	0096 4 22	200
M4	25 mm	2.8 mm	WS7	70	A	0096 4 25	200
M4	30 mm	2.8 mm	WS7	70	A	0096 4 30	200
M4	35 mm	2.8 mm	WS7	70	A	0096 4 35	500
M4	40 mm	2.8 mm	WS7	70	A	0096 4 40	500
M4	45 mm	2.8 mm	WS7	70	B	0096 4 45	500
M4	50 mm	2.8 mm	WS7	70	B	0096 4 50	500
M4	55 mm	2.8 mm	WS7	70	B	0096 4 55	100
M4	60 mm	2.8 mm	WS7	70	B	0096 4 60	500
M4	70 mm	2.8 mm	WS7	70	B	0096 4 70	200
M4	80 mm	2.8 mm	WS7	70	B	0096 4 80	100
M5	6 mm	3.5 mm	WS8	70	A	0096 5 6	100
M5	8 mm	3.5 mm	WS8	70	A	0096 5 8	100
M5	10 mm	3.5 mm	WS8	70	A	0096 5 10	100
M5	12 mm	3.5 mm	WS8	70	A	0096 5 12	100
M5	14 mm	3.5 mm	WS8	70	A	0096 5 14	100
M5	16 mm	3.5 mm	WS8	70	A	0096 5 16	100
M5	18 mm	3.5 mm	WS8	70	A	0096 5 18	500
M5	20 mm	3.5 mm	WS8	70	A	0096 5 20	100
M5	22 mm	3.5 mm	WS8	70	A	0096 5 22	100
M5	25 mm	3.5 mm	WS8	70	A	0096 5 25	100
M5	30 mm	3.5 mm	WS8	70	A	0096 5 30	100
M5	35 mm	3.5 mm	WS8	70	A	0096 5 35	100
M5	40 mm	3.5 mm	WS8	70	A	0096 5 40	100
M5	45 mm	3.5 mm	WS8	70	A	0096 5 45	100
M5	50 mm	3.5 mm	WS8	70	A	0096 5 50	100
M5	55 mm	3.5 mm	WS8	70	B	0096 5 55	200
M5	60 mm	3.5 mm	WS8	70	B	0096 5 60	200
M5	65 mm	3.5 mm	WS8	70	B	0096 5 65	200
M5	70 mm	3.5 mm	WS8	70	B	0096 5 70	200
M5	75 mm	3.5 mm	WS8	70	B	0096 5 75	100
M5	80 mm	3.5 mm	WS8	70	B	0096 5 80	200
M5	95 mm	3.5 mm	WS8	70	B	0096 5 95	50