


HEXAGONAL BOLT WITH THREAD UP TO THE HEAD

ISO 4017, stainless steel A2-50 and A2-70, plain

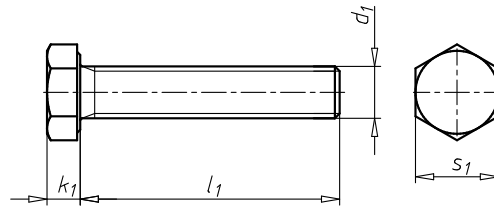

Thread type x nominal diameter (d ₁)	Length (l ₁)	Head height (k ₁)	External drive (s ₁)	Property class	Product class	Art. No.	P. Qty.
M8	8 mm	5.3 mm	WS13	70	A	0096 8 8	200
M8	10 mm	5.3 mm	WS13	70	A	0096 8 10	100
M8	12 mm	5.3 mm	WS13	70	A	0096 8 12	100
M8	14 mm	5.3 mm	WS13	70	A	0096 8 14	200
M8	15 mm	5.3 mm	WS13	70	A	0096 8 15	500
M8	16 mm	5.3 mm	WS13	70	A	0096 8 16	100
M8	18 mm	5.3 mm	WS13	70	A	0096 8 18	100
M8	20 mm	5.3 mm	WS13	70	A	0096 8 20	100
M8	22 mm	5.3 mm	WS13	70	A	0096 8 22	100
M8	25 mm	5.3 mm	WS13	70	A	0096 8 25	100
M8	27 mm	5.3 mm	WS13	70	A	0096 8 27	100
M8	28 mm	5.3 mm	WS13	70	A	0096 8 28	1500
M8	30 mm	5.3 mm	WS13	70	A	0096 8 30	100
M8	35 mm	5.3 mm	WS13	70	A	0096 8 35	100
M8	40 mm	5.3 mm	WS13	70	A	0096 8 40	100
M8	45 mm	5.3 mm	WS13	70	A	0096 8 45	100
M8	50 mm	5.3 mm	WS13	70	A	0096 8 50	100
M8	55 mm	5.3 mm	WS13	70	A	0096 8 55	100
M8	60 mm	5.3 mm	WS13	70	A	0096 8 60	100
M8	65 mm	5.3 mm	WS13	70	A	0096 8 65	100
M8	70 mm	5.3 mm	WS13	70	A	0096 8 70	100
M8	75 mm	5.3 mm	WS13	70	A	0096 8 75	100
M8	80 mm	5.3 mm	WS13	70	A	0096 8 80	100
M8	85 mm	5.3 mm	WS13	70	B	0096 8 85	100
M8	90 mm	5.3 mm	WS13	70	B	0096 8 90	100
M8	95 mm	5.3 mm	WS13	70	B	0096 8 95	50
M8	100 mm	5.3 mm	WS13	70	B	0096 8 100	50
M8	110 mm	5.3 mm	WS13	70	B	0096 8 110	50
M8	120 mm	5.3 mm	WS13	70	B	0096 8 120	50
M8	130 mm	5.3 mm	WS13	70	B	0096 8 130	50
M8	140 mm	5.3 mm	WS13	70	B	0096 8 140	25
M8	145 mm	5.3 mm	WS13	70	B	0096 8 145	40
M8	150 mm	5.3 mm	WS13	70	B	0096 8 150	25
M8	160 mm	5.3 mm	WS13	70	B	0096 8 160	50
M8	170 mm	5.3 mm	WS13	70	B	0096 8 170	50
M8	180 mm	5.3 mm	WS13	70	B	0096 8 180	50
M8	190 mm	5.3 mm	WS13	70	B	0096 8 190	50
M8	200 mm	5.3 mm	WS13	70	B	0096 8 200	100