


HEXAGONAL BOLT WITH THREAD UP TO THE HEAD

ISO 4017, stainless steel A2-50 and A2-70, plain

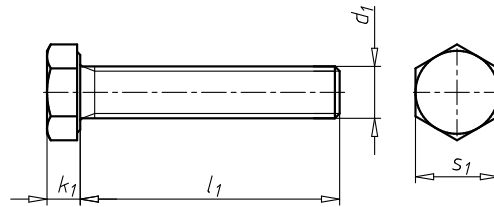

Thread type x nominal diameter (d ₁)	Length (l ₁)	Head height (k ₁)	External drive (s ₁)	Property class	Product class	Art. No.	P. Qty.
M10	10 mm	6.4 mm	WS16	70	A	0096 910 10	100
M10	12 mm	6.4 mm	WS16	70	A	0096 910 12	100
M10	16 mm	6.4 mm	WS16	70	A	0096 910 16	100
M10	20 mm	6.4 mm	WS16	70	A	0096 910 20	100
M10	25 mm	6.4 mm	WS16	70	A	0096 910 25	100
M10	30 mm	6.4 mm	WS16	70	A	0096 910 30	100
M10	35 mm	6.4 mm	WS16	70	A	0096 910 35	100
M10	40 mm	6.4 mm	WS16	70	A	0096 910 40	100
M10	45 mm	6.4 mm	WS16	70	A	0096 910 45	100
M10	50 mm	6.4 mm	WS16	70	A	0096 910 50	100
M10	55 mm	6.4 mm	WS16	70	A	0096 910 55	100
M10	60 mm	6.4 mm	WS16	70	A	0096 910 60	50
M10	65 mm	6.4 mm	WS16	70	A	0096 910 65	50
M10	70 mm	6.4 mm	WS16	70	A	0096 910 70	50
M10	80 mm	6.4 mm	WS16	70	A	0096 910 80	50
M10	85 mm	6.4 mm	WS16	70	A	0096 910 85	50
M10	90 mm	6.4 mm	WS16	70	A	0096 910 90	50
M10	100 mm	6.4 mm	WS16	70	A	0096 910 100	50
M10	110 mm	6.4 mm	WS16	70	B	0096 910 110	25
M10	120 mm	6.4 mm	WS16	70	B	0096 910 120	25
M10	130 mm	6.4 mm	WS16	70	B	0096 910 130	25
M10	140 mm	6.4 mm	WS16	70	B	0096 910 140	25
M10	150 mm	6.4 mm	WS16	70	B	0096 910 150	25
M10	160 mm	6.4 mm	WS16	70	B	0096 910 160	25
M10	180 mm	6.4 mm	WS16	70	B	0096 910 180	25
M10	200 mm	6.4 mm	WS16	70	B	0096 910 200	25