


HEXAGONAL BOLT WITH THREAD UP TO THE HEAD

ISO 4017, stainless steel A2-50 and A2-70, plain

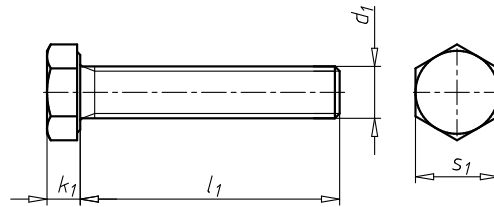

Thread type x nominal diameter (d ₁)	Length (l ₁)	Head height (k ₁)	External drive (s ₁)	Property class	Product class	Art. No.	P. Qty.
M12	20 mm	7.5 mm	WS18	70	A	0096 912 20	100
M12	25 mm	7.5 mm	WS18	70	A	0096 912 25	100
M12	30 mm	7.5 mm	WS18	70	A	0096 912 30	100
M12	35 mm	7.5 mm	WS18	70	A	0096 912 35	100
M12	40 mm	7.5 mm	WS18	70	A	0096 912 40	100
M12	45 mm	7.5 mm	WS18	70	A	0096 912 45	100
M12	50 mm	7.5 mm	WS18	70	A	0096 912 50	100
M12	55 mm	7.5 mm	WS18	70	A	0096 912 55	100
M12	60 mm	7.5 mm	WS18	70	A	0096 912 60	50
M12	65 mm	7.5 mm	WS18	70	A	0096 912 65	50
M12	70 mm	7.5 mm	WS18	70	A	0096 912 70	25
M12	75 mm	7.5 mm	WS18	70	A	0096 912 75	25
M12	80 mm	7.5 mm	WS18	70	A	0096 912 80	25
M12	90 mm	7.5 mm	WS18	70	A	0096 912 90	25
M12	100 mm	7.5 mm	WS18	70	A	0096 912 100	25
M12	110 mm	7.5 mm	WS18	70	A	0096 912 110	25
M12	120 mm	7.5 mm	WS18	70	A	0096 912 120	25
M12	130 mm	7.5 mm	WS18	70	B	0096 912 130	25
M12	140 mm	7.5 mm	WS18	70	B	0096 912 140	25
M12	150 mm	7.5 mm	WS18	70	B	0096 912 150	25
M12	160 mm	7.5 mm	WS18	70	B	0096 912 160	25
M12	170 mm	7.5 mm	WS18	70	B	0096 912 170	10
M12	180 mm	7.5 mm	WS18	70	B	0096 912 180	25
M12	190 mm	7.5 mm	WS18	70	B	0096 912 190	25
M12	200 mm	7.5 mm	WS18	70	B	0096 912 200	25
M12	250 mm	7.5 mm	WS18	70	B	0096 912 250	25
M14	35 mm	8.8 mm	WS21	70	A	0096 914 35	25
M14	55 mm	8.8 mm	WS21	70	A	0096 914 55	25
M14	65 mm	8.8 mm	WS21	70	A	0096 914 65	25
M14	120 mm	8.8 mm	WS21	70	A	0096 914 120	25
M14	130 mm	8.8 mm	WS21	70	A	0096 914 130	25
M14	140 mm	8.8 mm	WS21	70	A	0096 914 140	25