


# HEXAGONAL BOLT WITH THREAD UP TO THE HEAD

ISO 4017, stainless steel A2-50 and A2-70, plain

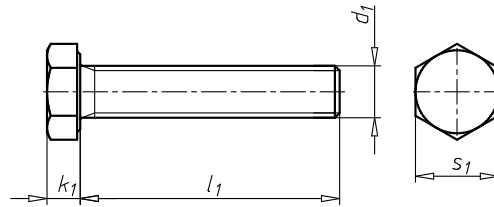

Thread type x nominal diameter (d <sub>1</sub> )	Length (l <sub>1</sub> )	Head height (k <sub>1</sub> )	External drive (s <sub>1</sub> )	Property class	Product class	Art. No.	P. Qty.
M16	12 mm	10 mm	WS24	70	A	<b>0096 16 12</b>	25
M16	16 mm	10 mm	WS24	70	A	<b>0096 16 16</b>	25
M16	20 mm	10 mm	WS24	70	A	<b>0096 16 20</b>	50
M16	25 mm	10 mm	WS24	70	A	<b>0096 16 25</b>	50
M16	30 mm	10 mm	WS24	70	A	<b>0096 16 30</b>	50
M16	35 mm	10 mm	WS24	70	A	<b>0096 16 35</b>	50
M16	40 mm	10 mm	WS24	70	A	<b>0096 16 40</b>	50
M16	45 mm	10 mm	WS24	70	A	<b>0096 16 45</b>	25
M16	50 mm	10 mm	WS24	70	A	<b>0096 16 50</b>	25
M16	55 mm	10 mm	WS24	70	A	<b>0096 16 55</b>	25
M16	60 mm	10 mm	WS24	70	A	<b>0096 16 60</b>	25
M16	65 mm	10 mm	WS24	70	A	<b>0096 16 65</b>	25
M16	70 mm	10 mm	WS24	70	A	<b>0096 16 70</b>	25
M16	75 mm	10 mm	WS24	70	A	<b>0096 16 75</b>	25
M16	80 mm	10 mm	WS24	70	A	<b>0096 16 80</b>	25
M16	85 mm	10 mm	WS24	70	A	<b>0096 16 85</b>	25
M16	90 mm	10 mm	WS24	70	A	<b>0096 16 90</b>	25
M16	95 mm	10 mm	WS24	70	A	<b>0096 16 95</b>	50
M16	100 mm	10 mm	WS24	70	A	<b>0096 16 100</b>	25
M16	110 mm	10 mm	WS24	70	A	<b>0096 16 110</b>	25
M16	120 mm	10 mm	WS24	70	A	<b>0096 16 120</b>	25
M16	130 mm	10 mm	WS24	70	A	<b>0096 16 130</b>	25
M16	140 mm	10 mm	WS24	70	A	<b>0096 16 140</b>	25
M16	150 mm	10 mm	WS24	70	A	<b>0096 16 150</b>	10
M16	160 mm	10 mm	WS24	70	B	<b>0096 16 160</b>	10
M16	170 mm	10 mm	WS24	70	B	<b>0096 16 170</b>	10
M16	180 mm	10 mm	WS24	70	B	<b>0096 16 180</b>	10
M16	190 mm	10 mm	WS24	70	B	<b>0096 16 190</b>	5
M16	200 mm	10 mm	WS24	70	B	<b>0096 16 200</b>	5
M16	210 mm	10 mm	WS24	70	B	<b>0096 16 210</b>	25
M18	35 mm	11.5 mm	WS27	70	A	<b>0096 18 35</b>	25
M18	40 mm	11.5 mm	WS27	70	A	<b>0096 18 40</b>	25
M18	45 mm	11.5 mm	WS27	70	A	<b>0096 18 45</b>	25
M18	50 mm	11.5 mm	WS27	70	A	<b>0096 18 50</b>	25
M18	55 mm	11.5 mm	WS27	70	A	<b>0096 18 55</b>	25
M18	60 mm	11.5 mm	WS27	70	A	<b>0096 18 60</b>	25
M18	65 mm	11.5 mm	WS27	70	A	<b>0096 18 65</b>	25
M18	70 mm	11.5 mm	WS27	70	A	<b>0096 18 70</b>	25
M18	80 mm	11.5 mm	WS27	70	A	<b>0096 18 80</b>	25
M18	90 mm	11.5 mm	WS27	70	A	<b>0096 18 90</b>	25
M18	100 mm	11.5 mm	WS27	70	A	<b>0096 18 100</b>	25
M18	110 mm	11.5 mm	WS27	70	A	<b>0096 18 110</b>	25
M18	120 mm	11.5 mm	WS27	70	A	<b>0096 18 120</b>	10
M18	130 mm	11.5 mm	WS27	70	A	<b>0096 18 130</b>	25