


HEXAGONAL BOLT WITH THREAD UP TO THE HEAD

ISO 4017, stainless steel A2-50 and A2-70, plain

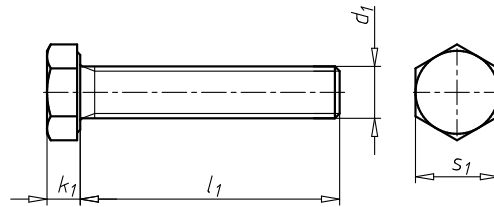

Thread type x nominal diameter (d ₁)	Length (l ₁)	Head height (k ₁)	External drive (s ₁)	Property class	Product class	Art. No.	P. Qty.
M30	40 mm	18.7 mm	WS46	50	B	0096 30 40	10
M30	55 mm	18.7 mm	WS46	50	B	0096 30 55	10
M30	60 mm	18.7 mm	WS46	50	B	0096 30 60	1
M30	65 mm	18.7 mm	WS46	50	B	0096 30 65	1
M30	70 mm	18.7 mm	WS46	50	B	0096 30 70	1
M30	80 mm	18.7 mm	WS46	50	B	0096 30 80	1
M30	85 mm	18.7 mm	WS46	50	B	0096 30 85	1
M30	90 mm	18.7 mm	WS46	50	B	0096 30 90	1
M30	100 mm	18.7 mm	WS46	50	B	0096 30 100	1
M30	110 mm	18.7 mm	WS46	50	B	0096 30 110	1
M30	120 mm	18.7 mm	WS46	50	B	0096 30 120	1
M30	130 mm	18.7 mm	WS46	50	B	0096 30 130	1
M30	140 mm	18.7 mm	WS46	50	B	0096 30 140	1
M30	150 mm	18.7 mm	WS46	50	B	0096 30 150	1
M30	250 mm	18.7 mm	WS46	50	B	0096 30 250	5
M33	90 mm	21 mm	WS50	50	B	0096 33 90	5
M33	120 mm	21 mm	WS50	50	B	0096 33 120	10
M36	50 mm	22.5 mm	WS55	50	B	0096 36 50	10
M36	70 mm	22.5 mm	WS55	50	B	0096 36 70	10
M36	80 mm	22.5 mm	WS55	50	B	0096 36 80	1
M36	90 mm	22.5 mm	WS55	50	B	0096 36 90	1
M36	100 mm	22.5 mm	WS55	50	B	0096 36 100	1
M36	120 mm	22.5 mm	WS55	50	B	0096 36 120	1
M36	140 mm	22.5 mm	WS55	50	B	0096 36 140	1
M36	150 mm	22.5 mm	WS55	50	B	0096 36 150	1