


PU COMPRESSED-AIR HOSE SET

Straight, assembled

Hose dia. in mm		Mounted coupling Art. No.	Length in m	PU hose Art. No.	Mounted plug-in nipple Art. No.	P. Qty.
Inside	Outside					
6.5	10.0	0699 100 765	10	0699 943 650	0699 100 865	1
8.0	12.0	0699 100 780		0699 943 811	0699 100 880	
11.0	16.0	0699 100 711		0699 943 115	0699 100 811	

PU COMPRESSED-AIR SPIRAL HOSE SETS

Assembled

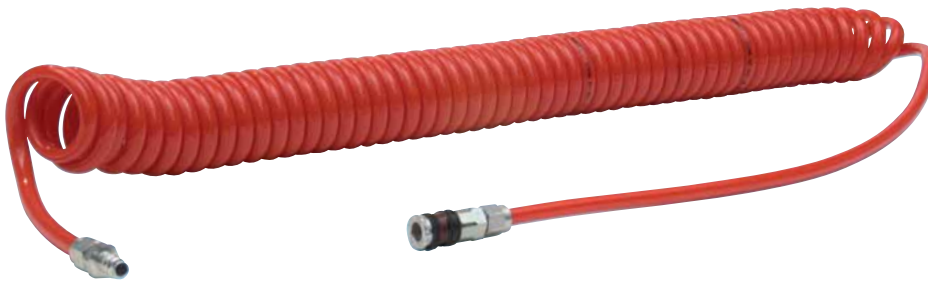

Complete with Series 2000 plug-in nipple and quick-action coupling.

Ready to use.

Straight ends simplify work.

High working comfort.

Maximum operating pressure of 10 bar.

High safety factor for user.

Hose dia. in mm		Mounted coupling Art. No.	Working length in m	Length when stretched in m	Diameter in mm	PU spiral hose set Art. No.	Mounted plug-in nipple Art. No.	P. Qty.
Inside	Outside							
6.5	10.0	0699 100 765	4	5	52	0699 941 650	0699 100 865	1
			8	10		0699 941 651		
8.0	12.0	0699 100 780	4	5	65	0699 941 811	0699 100 880	
			8	10		0699 941 812		
11.0	16.0	0699 100 711	8	10	95	0699 941 116	0699 100 811	