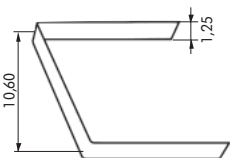
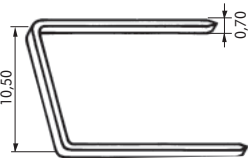
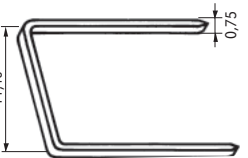



# WETTBEWERBSVERGLEICH KLAMMERN FÜR HAMMER- UND HANDTACKER

Klammern	Länge mm	Würth Art.-Nr.	Würth Geräte-Typ	Rapid Geräte-Typ	Bosch Geräte-Typ	Black&Decker Geräte-Typ	Esco Geräte-Typ	Novus Geräte-Typ
	6	<b>0480 140 006</b>	ST11/ST11Ergo/HT34	11/11E/14/34/44/44E/136/114	HTM57	-	11/11E	J19.../J030G/J031G
	8	<b>0480 140 008</b>	ST11/ST11Ergo/HT34	11/11E/14/34/44/44E/136/114	HTM57	-	11/11E	J19.../J030G/J031G
	10	<b>0480 140 010</b>	ST11/ST11Ergo/ST54/HT34	11/11E/54/34/44/44E/136/114	HTM57	-	11/11E	J19.../J030G/J031G
	12	<b>0480 140 012</b>	ST54/HT34	54/34/44/44E/136/114	-	-	-	J19...
	14	<b>0480 140 014</b>	ST54/HT34	54/34/44/44E/136/114	-	-	-	J19...
	4	<b>0480 113 004</b>	ST19/ST19Ergo	19/19E/13/13E/23	-	-	19/19E	J08ABH/J09ABH/J020H/J021H
	6	<b>0480 113 006</b>	ST19/ST19Ergo	19/19E/13/13E/23/30/33/63E/83E/135/113	-	-	19/19E	J08ABH/J09ABH/J020H/J021H/J19...
	8	<b>0480 113 008</b>	-	13/13E/23/30/33/63E/83E/135/213/113	-	-	-	J08ABH/J09ABH/J020H/J19...
	10	<b>0480 113 010</b>	-	13E/33/63E/83E/135/213/113	-	-	-	J19...
	6	<b>0480 153 006</b>	HT53/HT53Ergo	53/53E/153/253/253E/353/453E/530	HT8/HMT53/HT14	A5751/A5752/A5980	10/10E/20/30/30E/40/50E/90/20 prof./40 prof./HT53051/2/3/5	J06/J08/J08ABH/J09ABH/J14/17/18/J01/J02
	8	<b>0480 153 008</b>	HT53/HT53Ergo	53/53E/153/253/253E/353/453E/553/530	HT8/HMT53/HT14/PTK19E	A5751/A5752/A5980	10/10E/20/30/30E/40/50E/90/100/20 prof./40 prof./HT53051/2/3/5	J06/J08/J08ABH/J09ABH/J14/17/18/J01/J02

Nur für den internen Gebrauch!

## Hammertacker ST 54


### Ersatzteile

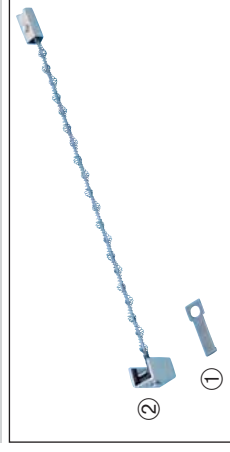

- ① Treiber: **Art.-Nr. 0714 854 901**
- ② Klammernschieber: **Art.-Nr. 0714 854 902**

## Hammertacker ST 11

### Ersatzteile

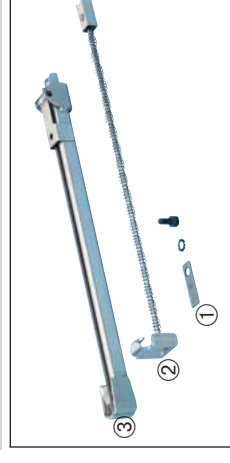

- ① Treiber: **Art.-Nr. 0714 811 901**
- ② Klammernschieber: **Art.-Nr. 0714 811 902**
- ③ Magazin: **Art.-Nr. 0714 811 903**