

## SNAP-OFF BLADE



Art. No.	0715 66 07	0715 66 05	0715 66 351
P. Qty.	10	10	10
Blade length	85 mm	110 mm	140 mm
Width of knife blade	9 mm	18 mm	25 mm
Thickness of blade	0.4 mm	0.5 mm	0.7 mm
Cutting edge length	80 mm	100 mm	125 mm

### Robust blade with long service life.


- Ice-hardened blade
- 3-facet cut
- In convenient dispenser

## BI-METAL KNIFE BLADES



Description	Art. No.	Pack Qty.
Knife Blades suit Retractable/Safety	0715 66 021	1

One box contains 10 blades.

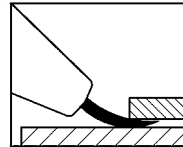

### Suit Retractable and Safety Knives.

#### Extremely safe to use.

Unbreakable under normal working conditions.

#### High economy and efficient working.

Triple the service life of standard blades.

#### Limber and flexible.

If necessary, the blade can be bent and worked with accordingly. (Special applications like this one are only possible with this blade.)

## PLASTIC RAZOR BLADE



Description	Wide of knife blade	Art. No.	Pack Qty.
Plastic Razor Blade	40 mm	0714 663 324	50

### Ideal for scraping delicate surfaces.

#### Perfect for removing materials from sensitive surfaces.

- Minimises the risk of damage.
- Ideal for scraping surface prone to scratching or marking.

#### Application area:

Ideal for scraping stickers, over spray and glues from surfaces.

## SAFETY RAZOR BLADE



Description	Art. No.	Pack Qty.
Safety Blades	0714 663 318	100

### Single edged razor blades.

- Ideal for cutting or use as scrapers.
- Compatible with both blade holders.
- Made in USA.
- Grade 12 heavy duty.
- Individually wrapped for edge and rust protection.