


POWERLOCS FLEECE

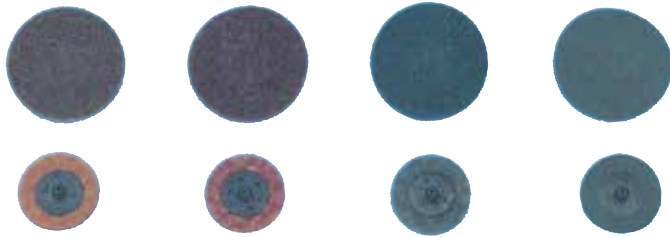

Diam. mm	Max. speed	Colour	Grain	Art. No.	Pack Qty.
50	23,000	Grey	Ultra fine	0673 205 040	10
		Blue	Fine	0673 205 028	
		Maroon	Medium	0673 205 018	
		Brown	Coarse	0673 205 010	
75	18,000	Grey	Ultra fine	0673 207 540	
		Blue	Fine	0673 207 528	
		Maroon	Medium	0673 207 518	
		Brown	Coarse	0673 207 510	

Twist lock backing compatible with all backing pads.

Ideal in confined spaces.

High speed.


Open flexible disk structure.

- Minimal heat generation.
- No clogging of the treated surface with rubbed-off particles.
- Optimal adaptation to the work piece - even surface structure.



Powerlock twist lock design.

POWERLOCS FIBRE

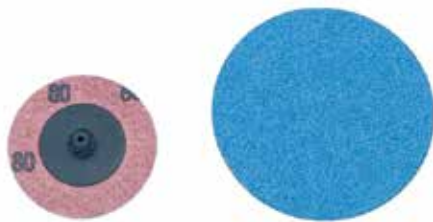

Diam. mm	Max. speed	Grain	Art. No.	Pack Qty.
50	30,000	36	0580 005 036	10
		60	0580 005 060	
		80	0580 005 080	
		120	0580 005 012	
75	20,000	36	0580 007 536	
		60	0580 007 560	
		80	0580 007 580	
		120	0580 007 512	

 
Twist lock backing compatible with all backing pads.

Material - Alumina Zirconia

- Ideal in confined spaces.
- Laminated, tough backing.
- High speed.

Application:

Grinding of weld seams, surface grinding, removal of paint, sharpening tools, de-burring, grinding of edges and finishing and rust removal.



Powerlock twist lock design.

POWERLOC ADAPTOR



For powerloc twist lock discs.

To suit:



Diameter	Art. No.	Pack Qty.
50mm (2")	0586 578 01	1
75mm (3")	0586 578 02	