

## COMFORT WINTER GLOVES



### Application area:


- For outdoor work in cold temperatures.
- Construction industry.
- Road construction.
- Supply and disposal companies.
- Tasks in refrigerated and normal warehouses.

### Two-layer knitted glove with excellent protection against cold.

- Acrylic/pure new wool fibre for maximum comfort.
- Open backs for excellent breathability.
- High-quality natural latex coating.
- Fine surface texture for outstanding wet and dry grip.

### Standards:

EN420 + EN388 + EN511  
Category II

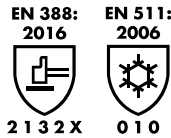

Size	Art. No.	Pack Qty.
8 - M	<b>0899 450 108</b>	1/6
9 - L	<b>0899 450 109</b>	
10 - XL	<b>0899 450 110</b>	
11 - XXL	<b>0899 450 111</b>	

## NITRILE GLOVE AQUASTOP



### Applications area:

Suitable for assembly work in wet or oily environments, e.g. in industry, automotive workshops, renovation work, masonry work etc.


### Water-resistant nitrile gloves with AquaGrip coating approved according to EN 420 and EN 388-4132.

### Water and oil-proof protection.

- Nitrile coating AquaGrip.
- Waterproof membrane.
- Offers complete protection against grease, oil, brake fluid and other substances that are harmful to the skin up to the knuckles.
- Keeps hands dry, even in wet weather.
- Good grip on wet substances.

### Standards:

EN 420 + EN 388  
Category II

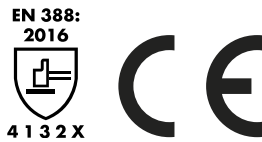

Size	Art. No.	Pack Qty.
7 - S	<b>0899 401 217</b>	1/12
8 - M	<b>0899 401 218</b>	
9 - L	<b>0899 401 219</b>	
10 - XL	<b>0899 401 220</b>	
11 - XXL	<b>0899 401 221</b>	

### Good fit and high level of wear resistance.

- Tight fitting, elasticated knitted cuff.
- Leaves no traces.

## CUT PROTECTION GLOVE W-200 LEVEL C



EN 388:  
2016



4 X 4 3 C

Size	Art. No.	Pack Qty.
7 - S	<b>0899 400 761</b>	1/6
8 - M	<b>0899 400 762</b>	
9 - L	<b>0899 400 763</b>	
10 - XL	<b>0899 400 764</b>	
11 - XXL	<b>0899 400 765</b>	

### Very comfortable and robust cut protection glove with Dyneema® fibres and breathable PU coating.

- Excellent hand temperature and optimal comfort for long periods thanks to Dyneema® fibres.
- Maximum comfort thanks to breathable PU coating.
- High degree of abrasion resistance and mechanical resistance.
- Good fit and flexibility.

Dyneema® is a registered trademark of DSM.

### Application area:

For applications with moderate cut protection and abrasion resistance requirements in dry work environments

Gauge	13
Material of the liner	Dyneema® polyamide/glass
Material Coating	Polyurethane
EN Standard	388,420
Cut resistance according to ISO 13997	C
Category	II