


DOUILLE 6 PANS FEMELLE 1/2" MÉTRIQUE

Exécution courte.

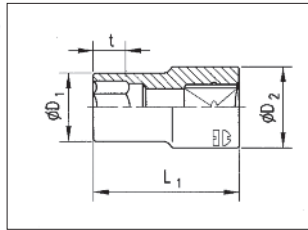

6 pans mm	L1 mm	D1 mm	D2 mm	t mm	Art. N°	Condit.
8	36	13	23	8	0712 131 108	1
9	36	14,2	23	9	0712 131 109	1
10	36	15,5	23	9	0712 131 110	1
11	36	16,7	23	10	0712 131 111	1
12	36	18	23	11	0712 131 112	1
13	36	19,2	23	11	0712 131 113	1
14	36	20,5	23	13	0712 131 114	1
15	36	21,7	23	13	0712 131 115	1
16	36	23	23,2	13	0712 131 116	1
17	36	24,2	23,2	13	0712 131 117	1
18	36	25,5	23,5	14	0712 131 118	1
19	36	26,7	24,7	14	0712 131 119	1
20	36	28	25,5	14	0712 131 120	1
21	38	29,2	26	14	0712 131 121	1
22	38	30,5	26,5	16	0712 131 122	1
23	38	31,7	27,7	16	0712 131 123	1
24	38	33	29	18	0712 131 124	1
26	38	35,5	31,5	18	0712 131 126	1
27	44	36,7	32,2	20	0712 131 127	1
28	44	38	33,5	20	0712 131 128	1
30	44	40,5	36	22	0712 131 130	1
32	44	43	38,1	24	0712 131 132	1

Matière :

Finition chromée polie/mate.

Produits associés :

Cliquet réversible 1/2"

Kit réparation cliquet 1/2"

Poignée coulissante 1/2"

Rallonge 1/2"

Cardan 1/2"

Réducteur Augmentateur