


RONDELLE PIANE

DIN 125 A, UNI 6592

- durezza secondo Vickers: 140 HV (per le rondelle in acciaio e acciaio inox)

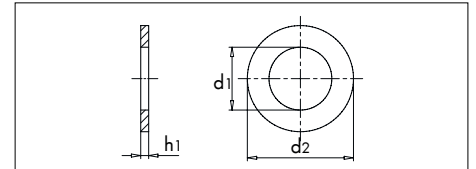

per viti	Ø interno d ₁ [mm]	Ø esterno d ₂ [mm]	spess. h ₁ [mm]	acciaio grezzo Art.	acciaio zincato bianco Art.	acciaio inox A2 Art.	acciaio inox A4 Art.	ottone lucido Art.	poliammide PA Art.
M2	2,2	5	0,3	0405 2	0407 2	0409 2	0412 2	—	0421 002
M2,5	2,7	6	0,5	0405 25	0407 25	0409 25	0412 25	—	0421 002 5
M3	3,2	7	0,5	0405 3	0407 3	0409 3	0412 3	0400 3	0421 003
M4	4,3	9	0,8	0405 4	0407 4	0409 4	0412 4	0400 4	0421 004
M5	5,3	10	1,0	0405 5	0407 5	0409 5	0412 5	0400 5	0421 005
M6	6,4	12	1,6	0405 6	0407 6	0409 6	0412 6	0400 6	0421 006
M7	7,4	14	1,6	0405 7	0407 7	0409 7	0412 7	0400 7	0421 007
M8	8,4	16	1,6	0405 8	0407 8	0409 8	0412 8	0400 8	0421 008
M10	10,5	20	2	0405 10	0407 10	0409 10	0412 10	0400 10	0421 001 0
M12	13	24	2,5	0405 12	0407 12	0409 12	0412 12	0400 12	0421 001 2
M14	15	28	2,5	0405 14	0407 14	0409 14	0412 14	0400 14	0421 001 4
M16	17	30	3	0405 16	0407 16	0409 16	0412 16	0400 16	0421 001 6
M18	19	34	3	0405 18*	0407 18*	0409 18	0412 18	0400 18	0421 001 8
M20	21	37	3	0405 20*	0407 20*	0409 20	0412 20	0400 20	0421 002 0
M22	23	39	3	0405 22*	0407 22*	0409 22	0412 22	—	0421 002 2
M24	25	44	4	0405 24*	0407 24*	0409 24	0412 24	0400 24	0421 002 4
—	27	50	4	0405 26*	0407 26*	—	—	—	—
M27	28	50	4	0405 27*	0407 28*	0409 27	0412 27	—	0421 002 8
M30	31	56	4	0405 30*	0407 30*	0409 30	0412 30	—	0421 003 0
M33	34	60	5	0405 33*	0407 33*	0409 33	0412 33	—	—
M36	37	66	5	0405 36*	0407 36*	0409 36	0412 36	—	—

* forma B - smussata

ASSORTIMENTI RONDELLE PIANE IN VALIGETTA SYSKO



Art. 5964 040 700

Rondelle piane DIN 125, zincate bianche (A2K)

Contenuto:
1425 pz. di misure da M3 a M20



Art. 5964 040 702

Rondelle piane/grembialine DIN 125/DIN 522 zincate bianche (A2K)

Contenuto:
1125 pz. misure da: M4 a M16/M5 a M10