


GOMITO A 90° INTERMEDIO

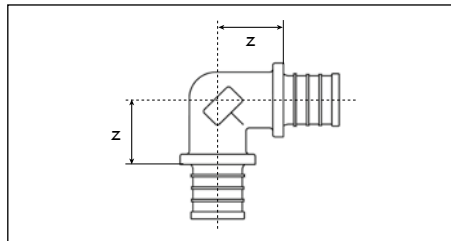


- in ottone CW617N, superficie stagnata

misure	z [mm]	peso [g]	Art.
14 x 14*	14	46	0878 674 033
16 x 16	18	46	0878 674 110
20 x 20	21	76	0878 674 220
25 x 25	25,5	136	0878 674 330
32 x 32	30	232	0878 674 440
40 x 40	43	448	0878 674 550
50 x 50	48	706	0878 674 660
63 x 63	58,5	1159	0878 674 770

* superficie non stagnata


GOMITO A 45° INTERMEDIO

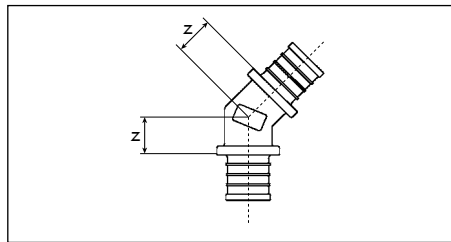

- in ottone CW617N, superficie stagnata

misure	z [mm]	peso [g]	Art.
16 x 16	18	48	0878 675 110
20 x 20	17	70	0878 675 220
25 x 25	18	114	0878 675 330
32 x 32	18	182	0878 675 440
40 x 40	24	352	0878 675 550
50 x 50	30	554	0878 675 660
63 x 63	35,5	902	0878 675 770

GOMITO A 90° MASCHIO

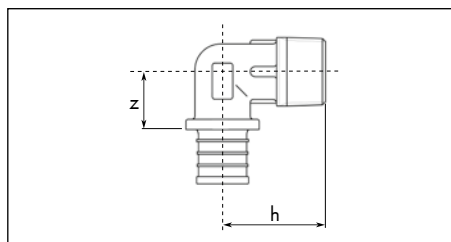

- in ottone CW617N, superficie stagnata

misure	z [mm]	h [mm]	peso [g]	Art.
16 x R 1/2"	18	34	68	0878 674 150
20 x R 1/2"	20	36,5	86	0878 674 250
20 x R 3/4"	20	38	102	0878 674 260
25 x R 3/4"	23	41	142	0878 674 360
32 x R 3/4"	26	50	230	0878 674 460
32 x R 1"	26,5	52	252	0878 674 470