


## Sleufschroevendraaier

### Ronde kling

- Kling: Matverchroomd
- Aandrijving: DIN 5264-A, ISO 2380, Black Point
- Norm: SMS SS 2830, DIN 5265

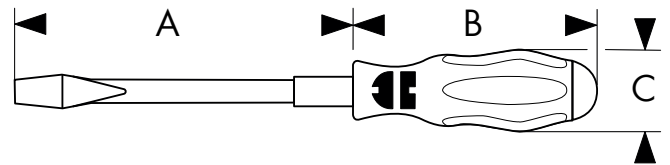

Dikte van snijrand x breedte van snijrand	Bladlengte (A)	Handvatlengte/handvatbreedte	Art.nr.	VE
0,4 x 2,5 mm	75 mm	73/20 mm	<b>0613 231 725</b>	1
0,6 x 3,5 mm	100 mm	83/27 mm	<b>0613 231 735</b>	1
0,8 x 4 mm	100 mm	83/27 mm	<b>0613 231 74</b>	1
1 x 5,5 mm	150 mm	96/31 mm	<b>0613 231 755</b>	1