



## SKRUTKOVAČ, KRÍŽOVÝ PH

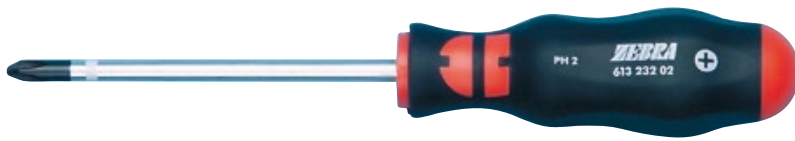


- Čepel: okrúhla, matné pochrómovanie
- Hrot: DIN 5260-PH, ISO 8764-PH, Black Point
- Norma: DIN 5262, SMS SS 283 1

	A mm	B/C mm	A palce	Obj.č.	Bal./ks
PH 1	80	96/31	3 1/8"	<b>0613 232 01</b>	1
PH 2	100	106/35	4"	<b>0613 232 02</b>	1
PH 3	150	114/38	6"	<b>0613 232 03</b>	1
PH 4	200	120/41	8"	<b>0613 232 04</b>	1



### Dlhý


- Čepel: oblá, matné pochrómovanie, dlhé prevedenie
- Hrot: DIN 5260-PH, ISO 8764-PH, Black Point
- Norma: DIN 5262, SMS SS 283 1

	A mm	B/C mm	A palce	Obj.č.	Bal./ks
PH 1	300	96/31	12"	<b>0613 262 1</b>	1
PH 2	300	106/35	12"	<b>0613 262 2</b>	1



### Krátky

- Čepel: oblá, matné pochrómovanie, krátke prevedenie
- Hrot: DIN 5260-PH, ISO 8764-PH, Black Point
- Norma: DIN 5262, SMS SS 283 1

	A mm	B/C mm	A palce	Obj.č.	Bal./ks
PH 1	25	62/31	1 3/4"	<b>0613 252 1</b>	1
PH 2	25	62/31	1 3/4"	<b>0613 252 2</b>	1