



Çift Taraflı Anahtar


Model: Metrik.

Standart: DIN 3110 / ISO 1085.


Malzeme: Krom vanadyum çelik.

Yüzey: kromajlı, başlık polisajlı.

Geometri: Ağız konumu 15°, yüksek yükler için sağlam başlıklar.

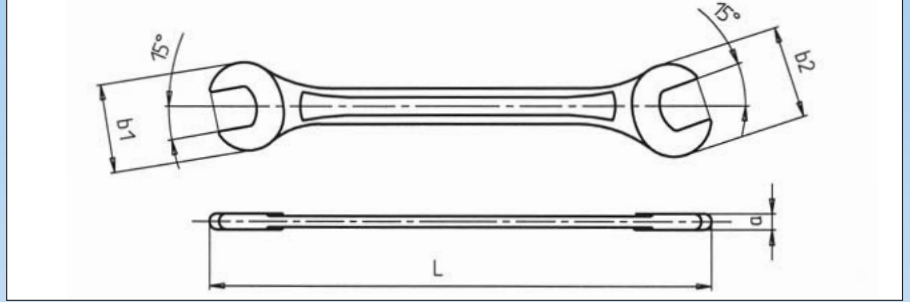

mm	U mm	b ₁ mm	b ₂ mm	a mm	Art.-Nr.	
4x5	100	12	13	3,3	0713 304 045	1/10
5x5,5	112	13	14	3,5	0713 304 055	
6x7	125	14	16	3,7	0713 304 067	
8x9	138	18	20	3,9	0713 304 089	
8x10	146	18	22,5	4,5	0713 304 080	
10x11	158	22,5	25	5	0713 304 101	
10x13	168	22,5	29	5,5	0713 304 103	
12x13	175	27	29	5,5	0713 304 123	
13x17	200	29	38	6,5	0713 304 137	
14x15	185	31	33,5	6	0713 304 145	
16x17	205	36	38	6,5	0713 304 167	
16x18	212	36	40	7	0713 304 168	
17x19	220	38	42	7	0713 304 179	
18x19	225	40	42	7,5	0713 304 189	
20x22	238	45	49	8	0713 304 202	
21x23	246	47	51	8	0713 304 213	
22x24	256	49	53	9	0713 304 224	
24x26	268	53	57	9	0713 304 246	
24x27	275	53	59	9	0713 304 247	
25x28	285	55	62	9	0713 304 258	
27x29	295	59	63,5	10	0713 304 279	
30x32	310	65	69	10	0713 304 302	1/5
30x34	325	65	73	11	0713 304 304	

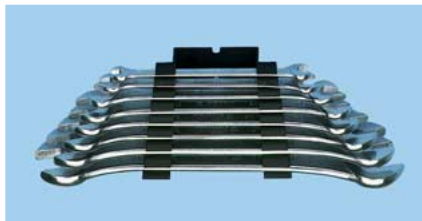

Çift taraflı anahtar seti

Set	mm	Art.-Nr.	
8	6x7, 8x9, 10x11, 12x13, 14x15, 16x17, 18x19, 20x22	0713 304 40 ¹⁾	1
10	6x7, 8x9, 10x11, 12x13, 14x15, 16x17, 18x19, 20x22, 21x23, 24x27	0713 304 41 ²⁾	
10	6x7, 8x9, 10x11, 12x13, 14x15, 16x17, 18x19, 20x22, 24x27, 30x32	0713 304 42 ³⁾	
12	6x7, 8x9, 10x11, 12x13, 14x15, 16x17, 18x19, 20x22, 21x23, 24x27, 25x28, 30x32	0713 304 43 ⁴⁾	
Aksesuar:			1
1) plastik tutucu dahil		0713 304 401	
2) plastik tutucu dahil		0713 304 411	
3) plastik tutucu dahil		0713 304 421	
4) plastik tutucu dahil		0713 304 431	