


1/2" LOKMALAR

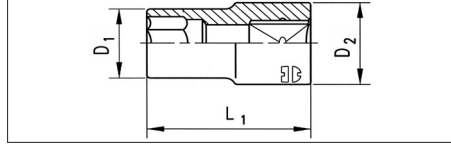



Dış T civatalar için

- Model: Kromajlı, polisajlı/mat
- Kafa tipi: 1/2", bilya oluklu
- Dış kafa tipi: TX
- Geometri: Kısa

¹ Geometri: uzun

		L ₁	D ₁	D ₂	Art.-Nr.	Amb./Ad.
	mm	mm	mm	mm		
10	9,43	40	12,3	22,5	0715 132 10	1
11	10,1	40	13,3	22,5	0715 132 11	1
12	11,18	40	14,3	22,5	0715 132 12	1
14	12,91	40	15,8	22,5	0715 132 14	1
16	14,76	40	19,6	22,5	0715 132 16	1
18	16,72	40	21,0	22,5	0715 132 18	1
20	18,5	40	22,5	23,0	0715 132 20	1
24	22,17	40	27,5	28,0	0715 132 24	1
10	9,43	77	12,3	22,5	0715 132 101¹	1
12	11,18	77	14,3	22,5	0715 132 121¹	1
14	12,91	77	15,8	22,5	0715 132 141¹	1

1/2" TORNAVIDA LOKMALARI

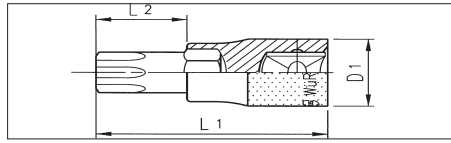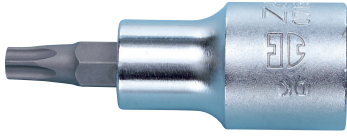


- Model: Kromajlı, polisajlı/mat
- Kafa tipi: 1/2", bilya oluklu
- İç kafa tipi: TX
- Geometri: Kısa

Uygulama örnekleri:

- TX 60 diskli fren Actros
- HL tahrik aksı Actros
- TX 80 direksiyon mili kolu Iveco
- direksiyon sistemi MAN
- TX 100 direksiyon mili kolu Iveco

		L ₁	U ₂	D ₁	Art.-Nr.	Amb./Ad.
	mm	mm	mm	mm		
20	3,84	60	20	22,5	0715 133 20	1
25	4,4	60	20	22,5	0715 133 25	1
27	4,96	60	20	22,5	0715 133 27	1
30	5,49	60	20	22,5	0715 133 30	1
40	6,6	60	20	22,5	0715 133 40	1
45	7,77	60	20	22,5	0715 133 45	1
50	8,79	60	20	22,5	0715 133 50	1
55	11,17	60	20	22,5	0715 133 55	1
60	13,2	60	20	22,5	0715 133 60	1
70	15,49	60	20	25,0	0715 133 70	1
80	17,51	60	20	28,0	0715 133 80	1
90	19,9	60	42	26,0	0715 133 90	1
100	22,1	80	42	26,0	0715 133 100	1

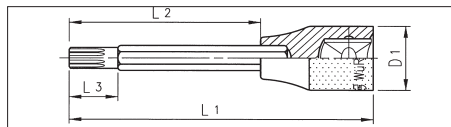

- Model: Kromajlı, polisajlı/mat
- Kafa tipi: 1/2", bilya oluklu
- İç kafa tipi: TX
- Geometri: Uzun
- Uygulamalar: Özellikle Ford için

¹ Ford Mondeo için silindir kafası

		L ₁	L ₂	L ₃	D ₁	Art.-Nr.	Amb./Ad.
	mm	mm	mm	mm	mm		
30	5,49	120	80	12,5	22,5	0715 134 30	1
40	6,6	120	80	12,5	22,5	0715 134 40	1
45	7,77	120	80	12,5	22,5	0715 134 45	1
50	8,79	120	80	-	22,5	0715 134 50	1
55	11,17	140	100	-	22,5	0715 134 55	1
60	13,2	140	100	-	22,5	0715 134 60	1
70	15,49	140	100	-	25,0	0715 134 70	1