



## 1/4" JOINTED RATCHET

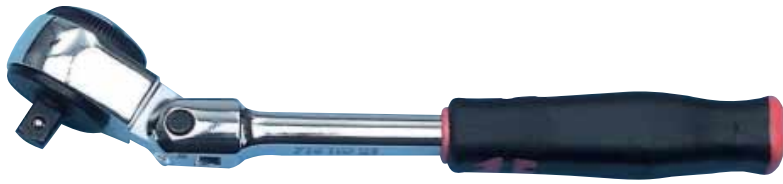


- Standard: DIN 3122, ISO 3315
- Head: 72 teeth, 5° rotating angle
- Design: Chrome-plated
- Head: Joint can be rotated 180°
- Accessories: Maintenance instructions, spare part set

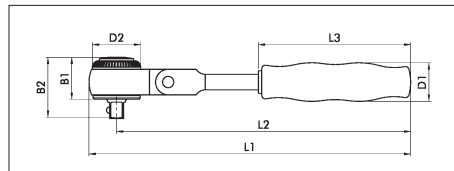

L1 in mm	L2 in mm	L3 in mm	B1 in mm	B2 in mm	D1 in mm	D2 in mm	Art. No.	P. Qty.
150	137	66	19	28	16	22	<b>0714 110 21</b>	1
Maintenance Set							<b>0712 001</b>	1


## 6" JOINTED HANDLE

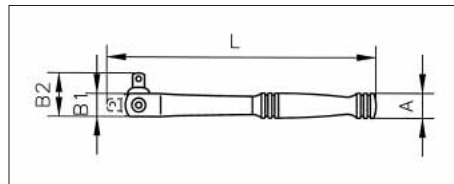

- Standard: DIN 3122, ISO 3315
- Joint: Rotatable by 180°, head is braked in any desired position
- Version: Chrome-plated, polished
- Use:
  - The 180° joint enables proper, flexible operation even when obstacles are encountered
  - Powerful tightening

L in mm	B1 in mm	B2 in mm	A in mm	L	Art. No.	P. Qty.
150	12	22.5	13	6"	<b>0713 110 101</b>	1/5


## 1/4" CROSS HANDLE

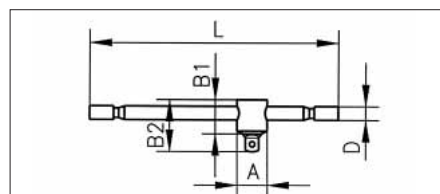

- Standard: DIN 3122, ISO 3315
- Sliding handle features ball detent
- Version: Chrome-plated, polished
- Use: T- or L-handle

L in mm	B1 in mm	B2 in mm	D in mm	A in mm	Art. No.	P. Qty.
115	15.5	24	6	14	<b>0713 110 201</b>	1/5

## SCREWDRIVER WITH 1/4" TIP

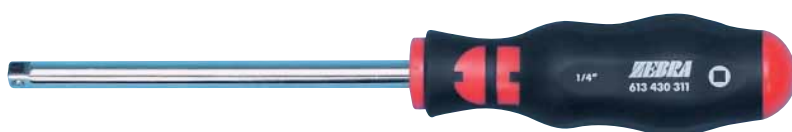

- Blade: Round, chrome-plated
- Tip: DIN 3126-A 6,3
- Use: Mounting of
- Socket wrench inserts, square

Standard	A in mm	B/C in mm	A	Art. No.	P. Qty.
1/4"	110	106/35	4 3/8"	<b>0613 430 311</b>	1