




Length mm	S mm	w x h mm	Weight g	Art. No.	Pack Qty.
125	16	14 x 9	100	0714 63 01	1
150	18	17 x 11	170	0714 63 02	
175	22	20 x 12	260	0714 63 03	
200	25	23 x 13	380	0714 63 04	
250			490	0714 63 05	
300			600	0714 63 06	

Flat Chisel

According to DIN 6453

- Tempered striking head.

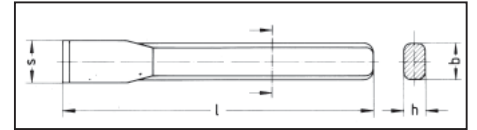

Length mm	S mm	w x h mm	Weight g	Art. No.	Pack Qty.
125	5	14 x 9	90	0714 63 07	1
150	6	17 x 11	160	0714 63 08	
200	8	20 x 12	335	0714 63 09	
250	10	23 x 13	455	0714 63 10	

Slotting Chisel

According to DIN 6451

- Tempered striking head.

 


Length mm	S mm	a mm	Weight g	Art. No.	Pack Qty.
200	22	14	225	0714 63 109	1
300	24	16	475	0714 63 11	
400	28	18	800	0714 63 12	

Stone- or Brick Chisel

According to DIN 7254, Form B

- Tempered striking head.



Length mm	a mm	Weight g	Art. No.	Pack Qty.
200	14	225	0714 63 129	1
300	16	450	0714 63 13	
400	18	765	0714 63 14	

Pointed Chisel

According to DIN 7256

- Tempered striking head.

