

RATCHET SCREWDRIVER REVERSIBLE-BIT PRODUCT LINE




Variable plug-in system for all hexagon bits with 6.35 mm = 1/4" mount

The right ratchet screwdriver for any application:


- Pistol Screwdriver with Bit Magazine and LED Light
Art. No. 0613 640 0-2
- T-Handle Screwdriver
Art. No. 0613 630 40
- Mini-Screwdriver
Art. No. 0613 630 50

- Rugged ratchet function with 45 teeth.
Max. torque of up to 40 Nm.
- 3-position adjustment wheel. Can be adjusted with one hand.
Simple change of direction during work possible without using the other hand.

T-HANDLE RATCHET SCREWDRIVER

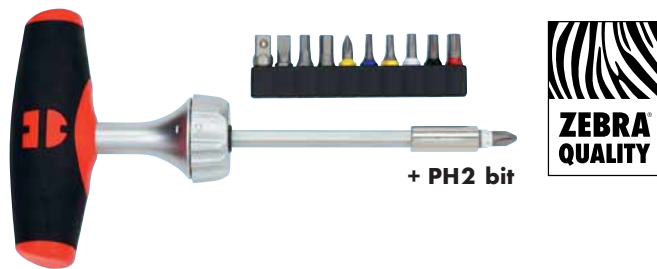


+ PH2 bit

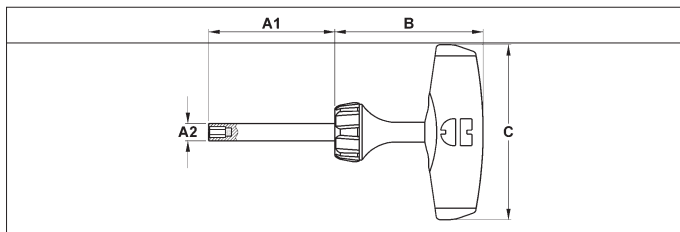

with 10-piece bit strip

- Handle: 2-component handle.
 - Blade: Long bit holder blade with magnet, bright chrome-plated.
 - Tip: DIN 3126-D 6.3.
- Use of the T-handle with high loosening torque or high tightening forces.

Contents of bit strip:

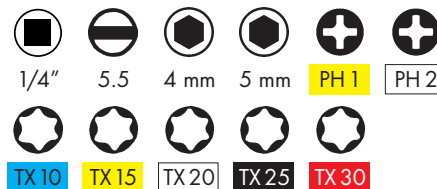


inches	A1 mm	B mm	C mm	A2 mm	Art. No.	VE/St.
1/4"	95	85	100	10	0613 630 40	1

MINI-RATCHET SCREWDRIVER




+ PH2 bit

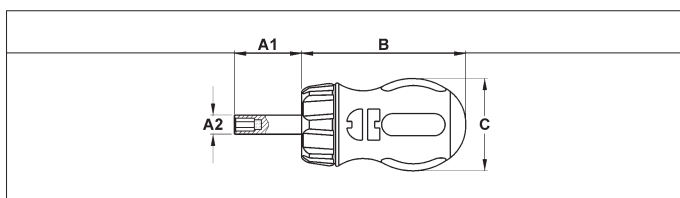

with 10-piece bit strip

- Handle: 2-component handle.
 - Blade: Short bit holder blade with magnet, bright chrome-plated.
 - Tip: DIN 3126-D 6.3.
- Enables applications in cramped spaces with high torque.

Contents of bit strip:

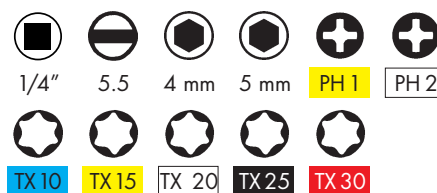

inches	A1 mm	B mm	C mm	A2 mm	Art. No.	P. Qty.
1/4"	26	70	38	20	0613 630 50	1