


CLIPS & CLAMPS – PLASTIC SPLIT RIVET

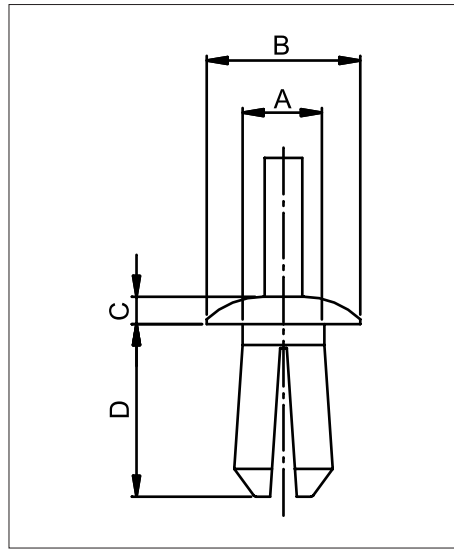

Art. No. 0501 101 627

Fig. No.: 49

Art. No.	Att. hole	Att. thickness	A	B	C	D	Color	Fig.	P. Qty.
0500 126 94	3.00-3.60	0.80-4.50	3.00	4.80	1.30	6.20	S	1	50
0500 143 00	3.50-3.70	2.00-5.00	3.50	8.00	2.20	8.00	S	2	50
0500 124 78	3.80-4.00	2.50-5.00	3.60	8.00	2.00	7.00	S	3	50
0501 121 118	4.00-4.20	2.00-6.00	-	8.00	1.00	8.50	S	4	100
0501 121 120	4.55-5.15	3.00-8.00	4.50	15.00	3.00	11.50	S	5	25
0500 128 21	5.00-5.20	0.75-3.00	3.00	8.50	2.00	6.00	S	6	25
0500 124 28	5.00-5.20	1.50-5.00	5.00	10.00	2.00	8.00	S	7	50
0501 167 058	5.00-5.20	5.50-12.00	5.00	10.00	2.00	15.00	S	8	50
0500 126 96	5.00-5.50	3.00-8.00	5.00	10.00	2.00	11.50	N	9	25
0500 521 4	5.00-5.50	3.00-8.00	5.00	10.00	2.00	11.50	S	10	50
0500 128 54	5.00-5.70	1.50-5.00	5.00	10.00	2.00	7.50	S	11	25
0500 491 00	5.05-5.55	6.00-11.00	5.00	10.00	2.00	15.00	S	12	50
0501 103 035	5.50-6.40	2.50-7.00	5.50	16.00	2.00	11.00	S	13	25
0500 554 00	5.60-6.60	5.00-11.00	5.60	9.00	2.00	16.00	S	14	50
0501 103 065	5.90-6.10	4.40-5.80	5.90	16.00	3.00	10.40	S	15	25
0501 101 652	5.90-7.10	2.00-8.00	5.80	10.00	2.00	12.00	N	16	100
0500 127 10	5.90-7.10	2.00-8.00	5.80	10.00	2.00	12.00	S	17	50
0500 718	6.00	5.00-5.50	6.00	13.00	2.00	10.00	S	18	25
0501 104 084	6.00-6.10	1.50-6.00	-	10.00	1.30	10.70	S	19	50
0501 105 064	6.00-6.20	2.00-10.00	6.50	15.00	3.50	15.00	S	20	50
0501 103 017	6.00-6.20	7.00-15.00	6.50	20.00	4.00	20.00	S	21	25
0501 105 065	6.00-6.20	7.00-15.00	6.50	15.00	4.00	20.00	S	22	50
0500 141 42	6.00-6.20	7.50-8.60	6.00	16.00	2.50	14.50	S	23	25
0501 101 347	6.00-8.00	7.20-7.40	8.00	15.00	1.50	11.50	S	24	100
0501 121 121	6.50	3.80-6.00	6.40	22.00	-	13.80	S	25	25
0501 105 063	6.50-6.60	2.00-10.00	6.50	20.00	2.00	15.00	S	26	50
0501 105 078	6.50-6.60	2.00-10.00	6.50	20.00	3.50	17.00	S	27	50
0501 105 035	6.50-6.60	2.80-11.00	6.50	20.00	5.00	15.00	S	28	50
0501 105 016	6.60	1.00-2.50	6.60	20.00	2.50	9.00	S	29	50
0500 136 680	6.80-7.00	5.50-8.50	6.80	22.00	-	11.70	G	30	25
0501 104 122	7.00-7.20	4.00-7.00	7.00	18.00	2.50	16.50	S	31	100
0501 103 015	7.80	-5.60	7.80	16.00	2.00	10.60	S	32	50
0500 937 7	7.80	2.40-6.80	7.80	12.30	1.00	11.00	S	33	100
0501 121 119	7.80-8.80	0.80-9.50	7.80	17.00	3.50	12.30	S	34	100
0501 101 000	7.90-8.70	4.00-7.00	7.90	16.00	2.00	12.00	S	35	100