


Sealing ring, copper filling seal shape C

Asbestos-free, shape C

An asbestos-free copper ring can be used anywhere (except in the presence of some strong acids) due to its corrosion resistance. Via special preheating, the metal ring's structure softens further so that, when under pressure, it can embed itself into all the uneven areas of the parts to be screwed together.



Material	Copper
Surface	Plain
Form	C
Max. temperature resistance	300 °C

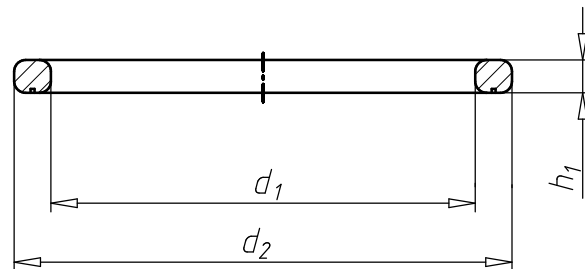

Outer diameter (d ₂)	Internal diameter (d ₁)	Thickness (h ₁)	Nominal size	RoHS-compliant	Corresponds to original spare part number	Art. no.	P. Qty.
9.9 mm	6.2 mm	1.5 mm	6 x 10 mm	Yes		0462 06 10	100
11.9 mm	8.2 mm	1.5 mm	8 x 12 mm	Yes		0462 08 12	100
13.9 mm	8.2 mm	1.5 mm	8 x 14 mm	Yes		0462 08 14	100
13.9 mm	10.2 mm	1.5 mm	10 x 14 mm	Yes		0462 010 14	2000
15.9 mm	10.2 mm	1.5 mm	10 x 16 mm	Yes		0462 010 16	100
15.9 mm	12.2 mm	2 mm	12 x 16 mm	Yes	VW/Audi: N.013 853.2	0462 012 16	100
17.9 mm	12.2 mm	2 mm	12 x 18 mm	Yes		0462 012 18	100
17.9 mm	14.2 mm	2 mm	14 x 18 mm	Yes		0462 014 18	500
19.9 mm	14.2 mm	2 mm	14 x 20 mm	Yes		0462 014 20	100
19.9 mm	16.2 mm	2 mm	16 x 20 mm	Yes		0462 016 20	100/2000
21.9 mm	16.2 mm	2 mm	16 x 22 mm	Yes		0462 016 22	50
21.9 mm	18.2 mm	2 mm	18 x 22 mm	Yes		0462 018 22	50
23.9 mm	18.2 mm	2 mm	18 x 24 mm	Yes		0462 018 24	50/100 /200
23.9 mm	20.2 mm	2 mm	20 x 24 mm	Yes		0462 020 24	50
25.9 mm	20.2 mm	2 mm	20 x 26 mm	Yes		0462 020 26	50
26.9 mm	22.2 mm	2 mm	22 x 27 mm	Yes		0462 022 27	100
28.9 mm	22.2 mm	2 mm	22 x 29 mm	Yes		0462 022 29	50
31.9 mm	24.3 mm	2.5 mm	24 x 32 mm			0462 024 32	50
31.9 mm	26.3 mm	2.5 mm	26 x 32 mm			0462 026 32	50
33.9 mm	28.3 mm	2.5 mm	28 x 34 mm			0462 028 34	50
37.9 mm	32.3 mm	2.5 mm	32 x 38 mm			0462 032 38	50
40.9 mm	35.3 mm	2.5 mm	35 x 41 mm			0462 035 41	50

Outer diameter (d ₂)	Internal diameter (d ₁)	Thickness (h ₁)	Nominal size	RoHS-compliant	Corresponds to original spare part number	Art. no.	P. Qty.
43.9 mm	38.3 mm	2.5 mm	38 x 44 mm			0462 038 44	50
54.9 mm	48.3 mm	2.5 mm	48 x 55 mm			0462 048 55	50

Notice

When using sealing washers, it should be noted that the dimensions are specified as internal and external diameters. If the correctly sized washer is not available, select the washer based on the internal diameter; for example a 10x12 washer can be replaced with a 10x14 or even a 10x16 washer.