



Sealing ring, vulcanised fibre, shape A

Shape A

A vulcanised fibre sealing washer is resistant to mineral oils, grease and weak acids, alcohols, ketones, esters, chlorinated hydrocarbons and has poor electric conductivity (insulation). It is preferably used for all water conduits and water pipes.

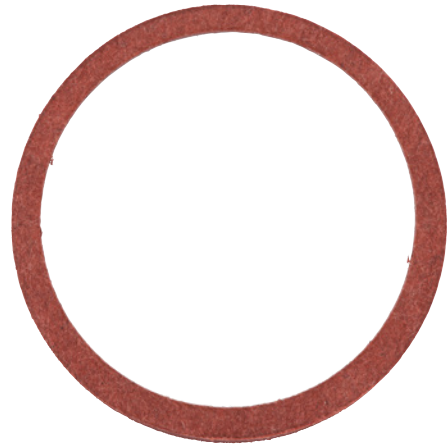

Material	Vulcanised fibre
Surface	Plain
Form	A
Max. temperature resistance	120 °C

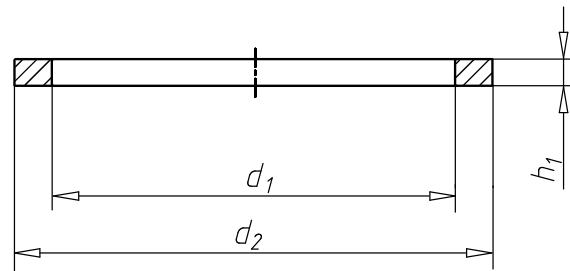

RoHS-compliant	Internal diameter (d ₁)	Outer diameter (d ₂)	Thickness (h ₁)	Corresponds to original spare part number	Art. no.	P. Qty.
	4.2 mm	7.9 mm	1 mm		0465 4 8	100/2000
	5.2 mm	8.9 mm	1 mm		0465 5 9	100/2000
	6.2 mm	9.9 mm	1 mm		0465 6 10	100
	6.2 mm	11.9 mm	1 mm		0465 6 12	100
	8.2 mm	11.9 mm	1 mm		0465 8 12	100
	8.2 mm	13.9 mm	1 mm		0465 8 14	100
	10.2 mm	13.9 mm	1 mm	VW/Audi: N.013 806.1	0465 10 14	100
	10.2 mm	15.9 mm	1 mm		0465 10 16	100
	12.2 mm	15.9 mm	1.5 mm		0465 12 16	100
	12.2 mm	17.9 mm	1.5 mm	VW/Audi: N.013 851.1	0465 12 18	100
	12.2 mm	18.9 mm	1.5 mm		0465 122 19	100/500
	14.2 mm	17.9 mm	1.5 mm		0465 14 18	100
	14.2 mm	19.9 mm	1.5 mm		0465 14 20	100
	14.2 mm	23.9 mm	1.5 mm		0465 142 24	100
	16.2 mm	19.9 mm	1.5 mm		0465 16 20	50
	16.2 mm	21.9 mm	1.5 mm		0465 16 22	100
	18.2 mm	21.9 mm	1.5 mm		0465 18 22	50
	18.2 mm	23.9 mm	1.5 mm		0465 18 24	100
	20.2 mm	23.9 mm	1.5 mm		0465 20 24	100
	20.2 mm	25.9 mm	1.5 mm		0465 20 26	100
	22.2 mm	26.9 mm	1.5 mm		0465 22 27	100
	22.2 mm	28.9 mm	1.5 mm		0465 22 29	100

RoHS-compliant	Internal diameter (d ₁)	Outer diameter (d ₂)	Thickness (h ₁)	Corresponds to original spare part number	Art. no.	P. Qty.
	24.3 mm	29.9 mm	2 mm		0465 24 30	100
	26.3 mm	31.9 mm	2 mm		0465 26 32	100
	27.3 mm	31.9 mm	2 mm		0465 27 32	100
	28.3 mm	33.9 mm	2 mm		0465 28 34	100
	30.3 mm	35.9 mm	2 mm		0465 30 36	100
Yes	15.2 mm	22.9 mm	1.5 mm		0465 15 23	100
Yes	32 mm	37.9 mm	2 mm		0465 32 38	100
Yes	33.3 mm	38.9 mm	2 mm		0465 33 39	100

Notice

When using sealing washers, it should be noted that the dimensions are specified as internal and external diameters. If the correctly sized washer is not available, select the washer based on the internal diameter; for example a 10x12 washer can be replaced with a 10x14 or even a 10x16 washer.