

System assortment 8.4.1, striking tool and files

24 pieces

Compatible with all products of the ORSY system world

Uniform grid dimensions

Attractive carbon finish

 
Insert made from high-quality plastic in attractive carbon finish for improved robustness, stability and easy cleaning

Find the correct tools quickly and easily

Tool sizes marked on insert.



ORSY




Number of pieces in assortment/set	24 PCS
Size foam section	8.4.1
Width x height x depth	462 x 38 x 335 mm

Decor	Art. no.	P. Qty.
Carbon appearance	0965 905 929	1
Carbon appearance, Black matt	0965 905 302	1

Details/Application

Suitable for the ORSY system world (e.g. system case, workshop trolley, ORSY®BULL boxes, ORSY shelves)

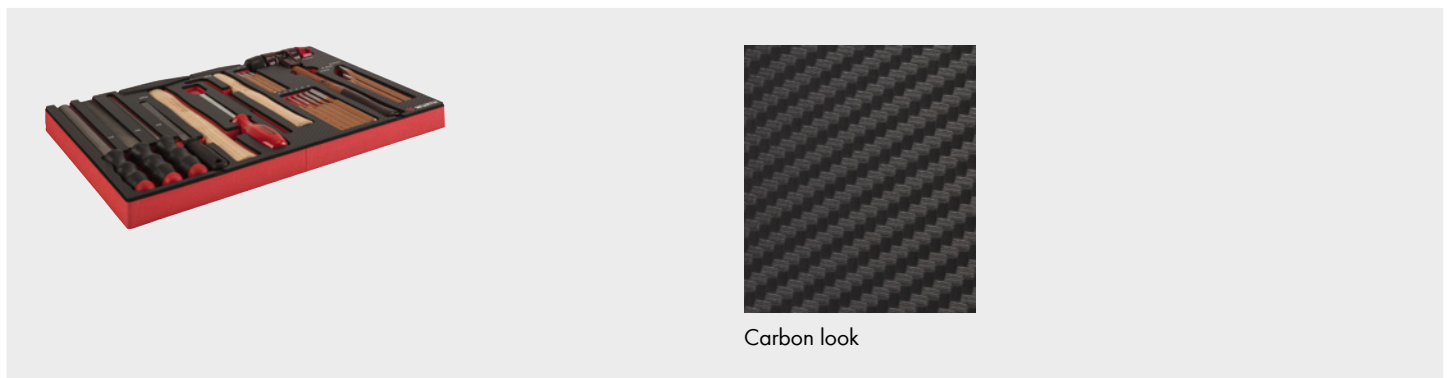

Carbon look

Contents for art. no. 0965 905 302		
Designation	Art. no.	Quantity
Seal scraper	0714 34 51	1
Flat blunt-ended file	0714 61 06	1
Half-round file	0714 61 38	1
Round file	0714 61 50	1
File handle	0714 61 622	3
Brake calliper file	0714 61 79	1
Flat chisel In line with DIN 6453 150 mm	0714 63 02	1
Flat chisel In line with DIN 6453 175 mm	0714 63 03	1
Cross cut chisel In line with DIN 6451 150 mm	0714 63 08	1

Designation	Art. no.	Quantity
Centre punch	0714 63 15	1
Drift punch According to DIN 6458 Spitzenbreite 2 mm	0714 63 18	1
Drift punch According to DIN 6458 Spitzenbreite 4 mm	0714 63 20	1
Pin punch Spitzenbreite 2 mm	0714 63 25	1
Pin punch Spitzenbreite 3 mm	0714 63 27	1
Pin punch Spitzenbreite 4 mm	0714 63 28	1
Pin punch Spitzenbreite 5 mm	0714 63 29	1
Pin punch Spitzenbreite 6 mm	0714 63 30	1
Pin punch Spitzenbreite 8 mm	0714 63 31	1
Scriber	0714 70 10	1
Simplex soft face hammer	0715 72 10	1
Machinists' hammer 200 g	0715 731 20	1
Machinists' hammer 500 g	0715 731 50	1
System insert 8.4.1, striking tool and files		1
Contents for art. no. 0965 905 929		
Designation	Art. no.	Quantity
Seal scraper	0714 34 51	1
Flat blunt-ended file	0714 61 06	1
Half-round file	0714 61 38	1
Round file	0714 61 50	1
File handle	0714 61 622	3
Brake calliper file	0714 61 79	1
Flat chisel In line with DIN 6453 150 mm	0714 63 02	1
Flat chisel In line with DIN 6453 175 mm	0714 63 03	1
Cross cut chisel In line with DIN 6451 150 mm	0714 63 08	1
Centre punch	0714 63 15	1
Drift punch According to DIN 6458 Width of tip 2 mm	0714 63 18	1
Drift punch According to DIN 6458 Width of tip 4 mm	0714 63 20	1
Pin punch Width of tip 2 mm	0714 63 25	1
Pin punch Width of tip 3 mm	0714 63 27	1
Pin punch Width of tip 4 mm	0714 63 28	1
Pin punch Width of tip 5 mm	0714 63 29	1
Pin punch Width of tip 6 mm	0714 63 30	1
Pin punch Width of tip 8 mm	0714 63 31	1
Scriber	0714 70 10	1
Simplex soft face hammer	0715 72 10	1
Machinists' hammer 200 g	0715 731 20	1
Machinists' hammer 500 g	0715 731 50	1
System insert 8.4.1, striking tool and files	0955 905 929	1