

## Paint spray, silk gloss

**Durable nitro-alkydal quality at a high technical level.**

### High-grade nitro-alkydal quality

- Easy to apply
- Very good coverage properties
- Quick-drying

**Can be coated with all common primers, filler products and paint types**

### Quick-drying paint resin

**Formula does not contain heavy metals**

### Drying time at 20 °C

- Dust-dry < 10 minutes
- Tack-free < 20 minutes
- Touch dry < 60 minutes



Illustration only


Contents	400 ml
Chemical basis	Nitroalkydale
Gloss level	Satin matt
Max. temperature resistance	80 °C

Colour	Art. no.	P. Qty.
Golden yellow RAL 1004	<b>0893 341 004</b>	1/6
Traffic yellow RAL 1023	<b>0893 341 023</b>	1/6
Pastel orange RAL 2003	<b>0893 342 003</b>	1/6
Flame red RAL 3000	<b>0893 343 000</b>	1/6
Gentian blue RAL 5010	<b>0893 345 010</b>	1/6
Sky blue RAL 5015	<b>0893 345 015</b>	1/6
Emerald green RAL 6001	<b>0893 346 001</b>	1/6
Signal grey RAL 7004	<b>0893 347 004</b>	1/6
Brown grey RAL 7013	<b>0893 347 013</b>	1/6
Slate grey RAL 7015	<b>0893 347 015</b>	1/6
Anthracite grey RAL 7016	<b>0893 347 016</b>	1/6
Blue grey RAL 7031	<b>0893 347 031</b>	1/6
Pebble grey RAL 7032	<b>0893 347 032</b>	1/6
Light grey RAL 7035	<b>0893 347 035</b>	1/6
Dusty grey RAL 7037	<b>0893 347 037</b>	1/6
Agate grey RAL 7038	<b>0893 347 038</b>	1/6
Traffic grey B RAL 7043	<b>0893 347 043</b>	1/6
Cream RAL 9001	<b>0893 349 001</b>	1/6
Grey white RAL 9002	<b>0893 349 002</b>	1/6
Signal white RAL 9003	<b>0893 349 003</b>	1/6
Signal black RAL 9004	<b>0893 349 004</b>	1/6
Jet black RAL 9005	<b>0893 349 005</b>	1/6
White aluminium RAL 9006	<b>0893 349 006</b>	1/6
Grey aluminium RAL 9007	<b>0893 349 007</b>	1/6
Pure white RAL 9010	<b>0893 349 010</b>	1/6

Colour	Art. no.	P. Qty.
Graphite black RAL 9011	<b>0893 349 011</b>	1/6
Satin black VW 110	<b>0893 349 110</b>	1/6
Dark grey VW 115	<b>0893 349 115</b>	1/6
Black Fiat 120	<b>0893 349 120</b>	1/6
Galinit grey MB 129	<b>0893 349 129</b>	1/6
Deep dark grey MB 167	<b>0893 349 167</b>	1/6
Actros grey MB 7329	<b>0893 347 329</b>	1/6
Nova grey MB 7350	<b>0893 347 350</b>	1/6
Argentite grey MB 7354	<b>0893 347 354</b>	1/6
Optional	<b>0893 330</b>	12

## Details/Application

For paint repair work, protection from corrosion and weathering, and for surface finishing. Surfaces: Wood, metal, fabric, stone, ceramics, glass, paintable plastics, concrete, wicker. Wide range of uses: Commercial vehicles, bodywork, radiators, window construction, steel construction etc.

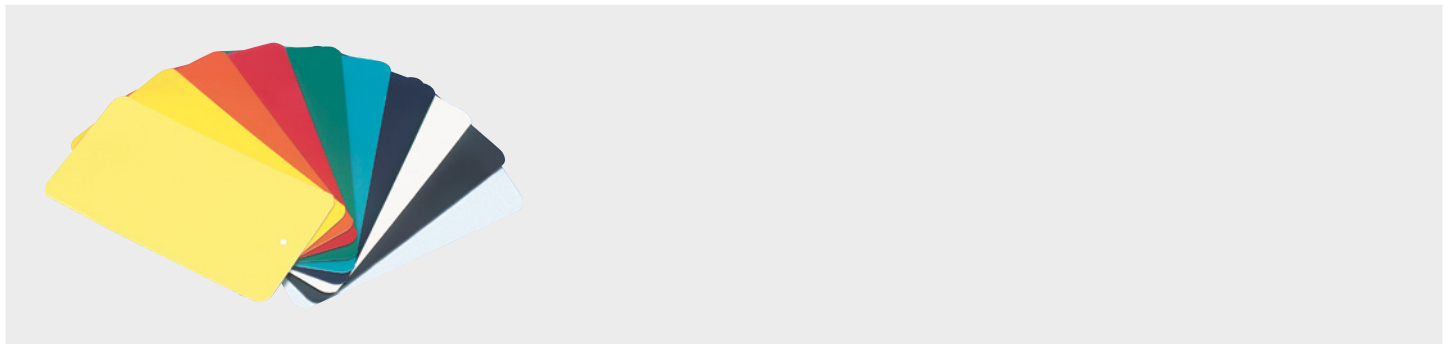

## Instructions

Shake the can vigorously for approx. 2 minutes before use. The surface must be clean, dry and free from grease. Remove rust and old loose paint; sand and prime. Spraying distance: 20-25 cm. Maintain a flash-off time of approx. 5 minutes between spray coatings.

The usage instructions are recommendations based on the tests we have conducted and our experience; carry out your own tests before each application. Due to the large number of applications and storage and processing conditions, we do not assume any liability for a specific application result. Insofar as our free customer service provides technical information or acts as an advisory service, no responsibility is assumed by this service except where the advice or information given falls within the scope of our specified, contractually agreed service or the advisor was acting deliberately. We guarantee consistent quality of our products. We reserve the right to make technical changes and further develop products.

Spare parts	Art. no.
Replacement spray head For spray cans Round nozzle	<b>0891 094</b>
Replacement spray head For spray cans Fan nozzle	<b>0891 095</b>

Related products	Art. no.
Spraymaster spray can attachment	<b>0891 090</b>
Silicone remover 1 l	<b>0893 222</b>
Silicone remover 5 l	<b>0893 222 5</b>