

## Perfect zinc spray

### Outstanding long-term protection and optimum metal surface appearance

#### High layer thickness in first spray pass

- High degree of safety thanks to optimum weathering protection
- Minimum amount of time spent, as only one operation is required
- Good coverage

#### Versatile use with adjustable spray head

Large area and minor repairs can be carried out quickly and reliably with the variable spray head.

#### High degree of resistance to running

#### High degree of wear resistance

#### Tested corrosion protection in accordance with DIN

- Perfect zinc spray, light: 250 hours
- Perfect zinc spray: 500 hours
- Can be used for repairs in accordance with DIN EN ISO 1461

#### Spot weldable




Contents	400 ml
----------	--------

Chemical basis	Colour	Gloss level	Art. no.	P. Qty.
Acrylic resin	Zinc	Matt	<b>0893 114 113</b>	1/12
Modified alkyd resin	Zinc, bright	Glossy	<b>0893 114 114</b>	1/12

## Details/Application

For visual enhancement, repair and protection against corrosion of metallic surfaces.

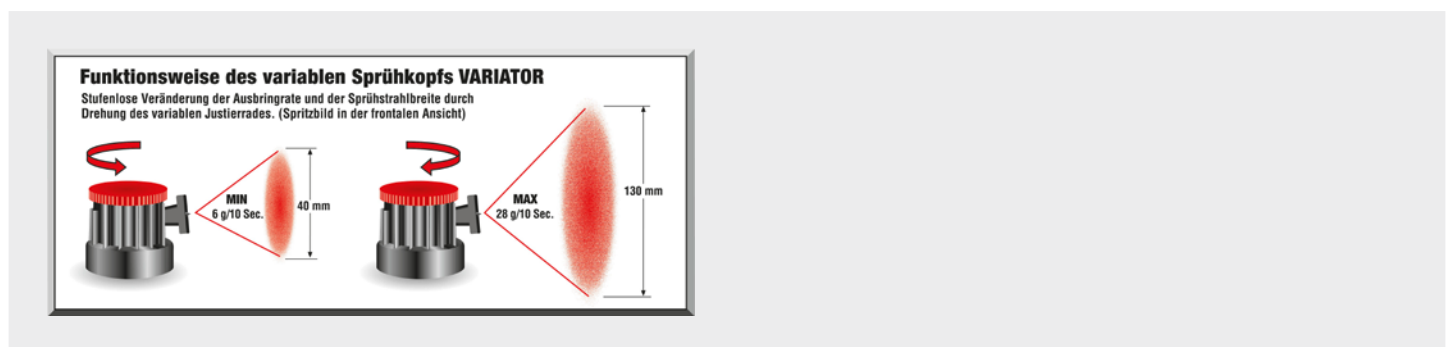


## Instructions

The application surface must be clean, dry and free from grease. Remove rust and old loose paint, then sand and clean. Shake can vigorously for at least 2 minutes before use.

## Notice

Perfect zinc spray and Perfect light zinc spray contain zinc, and therefore offer optimum, active cathodic protection against corrosion. If the surface is damaged, the zinc coating sacrifices itself (sacrificial anode), thereby protecting the metal against rust. The remaining products protect the entire surface against rust. If the surface is damaged, the metal is no longer protected. Not suitable as adhesive base for PU, MS polymer or hybrid sealing compounds.

### Corrosion protection after 250 hours of salt spray test according to DIN 50021 SS

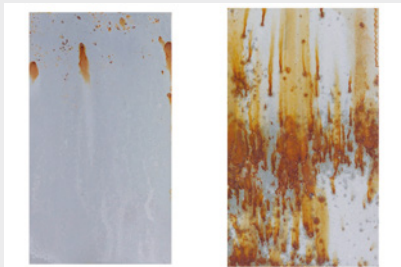

Zinc spray bright perfect and competitive product

The usage instructions are recommendations based on the tests we have conducted and our experience; carry out your own tests before each application. Due to the large number of applications and storage and processing conditions, we do not assume any liability for a specific application result. Insofar as our free customer service provides technical information or acts as an advisory service, no responsibility is assumed by this service except where the advice or information given falls within the scope of our specified, contractually agreed service or the advisor was acting deliberately. We guarantee consistent quality of our products. We reserve the right to make technical changes and further develop products.

Spare parts	Art. no.
Replacement spray head Variator	<b>0891 098</b>

Related products	Art. no.
Acetone cleaner Contents 0.25 l	<b>0893 460</b>

Related products for	Designation	Art. no.
0893 114 114	Acetone cleaner Contents 0.25 l	<b>0893 460</b>