

Hand-lever grease gun

For 400 g cartridges (DIN 1284, 235 x Ø 53.5 mm) or for 500 cm³ loose grease


- Feed quantity can be dispensed up to 1.5 cm³
- Working pressure 400 bar
- Maximum pressure up to over 800 bar
- Actuating force 50 to 330 N with feed pressures from 50 to 400 bar
- Complies with standard DIN 1283 (M10x1) and is tested to TÜV/GS, BLT and DLG standards
- Supplied with reinforced rubber hose and nozzle (M10x1)



Material	Steel
Max. working pressure	800 bar
Length	370 mm
Product weight (per item)	1298 g

Art. no. 0986 00

P. Qty.: 1

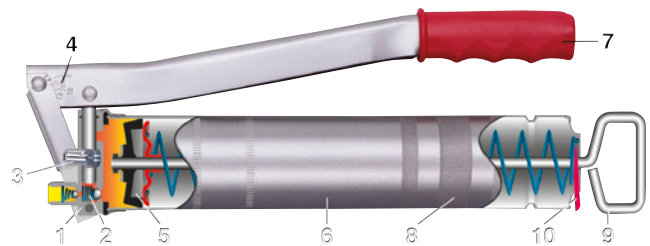

1. Precision steel pump mechanism, no false lubrication, no wearing seals.
2. Short-stroke feed system, grease feed possible at any opening angle, two inlet openings, good grease flow even at low temperatures.
3. Filling and bleeding valve. Filling possible with cartridges, loose grease and with filling unit.
4. Dosing scale for controlled grease outflow.
5. Grease and oil-resistant special sealing piston.
6. Rugged precision pipe.
7. Ergonomically shaped safety handle.
8. Anti-slip knurled marking in handle area.
9. Closed piston-rod handle.
10. Locking system – continuous, anti-slip piston rod locking – no accidental triggering!

Details/Application

For 400 g cartridges (DIN 1284, 235 x Ø 53.5 mm) or for 500 cm³ loose grease



Notice

Supplied with reinforced rubber hose and mouthpiece (M10x1)

Contents for art. no. 0986 00

Designation	Art. no.	Quantity
Reinforced rubber hose For one-handed, two-handed grease gun and lever grease gun	0986 002	1
Chuck For hand-lever grease gun	0986 003	1

Related products

	Art. no.
Metal feed piece For hand-lever grease gun	0986 001