


Drilling screw, flat head with recessed head, H pias®

Factory standard, galvanised steel, blue passivated (A3K), recessed head, H.

Material	Steel
Surface	Zinc plated
RoHS-compliant	Yes
Head type	Flat head
Drive type	H </td
Thread type	Self-tapping screw thread
Shape of tip	Drilling tip

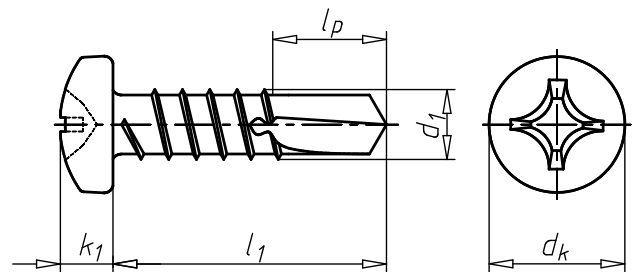

Nominal diameter (d_1)	Length (l_1)	Head diameter (d_k)	Head height (k_1)	Drill tip length (l_p)	Internal drive	Art. no.	P. Qty.
2.9 mm	13 mm	5.6 mm	2.2 mm	2.5 mm	H1	0211 29 13	1000
3.5 mm	9.5 mm	6.9 mm	2.6 mm	2.5 mm	H2	0211 35 95	1000
3.5 mm	13 mm	6.9 mm	2.6 mm	3 mm	H2	0211 35 13	1000
3.5 mm	16 mm	6.9 mm	2.6 mm	3 mm	H2	0211 35 16	1000 /2000
3.5 mm	19 mm	6.9 mm	2.6 mm	3 mm	H2	0211 35 19	1000
3.9 mm	13 mm	7.5 mm	2.8 mm	3.1 mm	H2	0211 39 13	1000
3.9 mm	16 mm	7.5 mm	2.8 mm	3.1 mm	H2	0211 39 16	1000
3.9 mm	19 mm	7.5 mm	2.8 mm	3.1 mm	H2	0211 39 19	1000
3.9 mm	22 mm	7.5 mm	2.8 mm	3.1 mm	H2	0211 39 22	1000
3.9 mm	25 mm	7.5 mm	2.8 mm	3.1 mm	H2	0211 39 25	1000
3.9 mm	32 mm	7.5 mm	2.8 mm	3.1 mm	H2	0211 39 32	500
4.2 mm	13 mm	8.2 mm	3.05 mm	3.7 mm	H2	0211 42 13	1000 /2000
4.2 mm	16 mm	8.2 mm	3.05 mm	3.7 mm	H2	0211 42 16	1000 /2000
4.2 mm	19 mm	8.2 mm	3.05 mm	3.7 mm	H2	0211 42 19	1000
4.2 mm	22 mm	8.2 mm	3.05 mm	3.7 mm	H2	0211 42 22	1000
4.2 mm	25 mm	8.2 mm	3.05 mm	3.7 mm	H2	0211 42 25	1000
4.2 mm	32 mm	8.2 mm	3.05 mm	3.7 mm	H2	0211 42 32	500/1500
4.8 mm	13 mm	9.5 mm	3.55 mm	4.5 mm	H2	0211 48 13	1000
4.8 mm	16 mm	9.5 mm	3.55 mm	4.5 mm	H2	0211 48 16	1000 /2000
4.8 mm	19 mm	9.5 mm	3.55 mm	4.5 mm	H2	0211 48 19	1000 /2000
4.8 mm	22 mm	9.5 mm	3.55 mm	4.5 mm	H2	0211 48 22	500/1000

Nominal diameter (d ₁)	Length (l ₁)	Head diameter (d _k)	Head height (k ₁)	Drill tip length (l _p)	Internal drive	Art. no.	P. Qty.
4.8 mm	25 mm	9.5 mm	3.55 mm	4.5 mm	H2	0211 48 25	500
4.8 mm	32 mm	9.5 mm	3.55 mm	4.5 mm	H2	0211 48 32	500
4.8 mm	38 mm	9.5 mm	3.55 mm	4.5 mm	H2	0211 48 38	500
4.8 mm	45 mm	9.5 mm	3.55 mm	4.5 mm	H2	0211 48 45	300
4.8 mm	50 mm	9.5 mm	3.55 mm	4.5 mm	H2	0211 48 50	300/500

Details/Application

